


## Metr.



|                       |                                                    |
|-----------------------|----------------------------------------------------|
| Material              | Nickel plated brass                                |
| Seal                  | VMQ (Silicone)                                     |
| O-Ring                | VMQ (Silicone)                                     |
| Protection            | IP 68 – 10 bar within the specified clamping range |
| Operating Temperature | -60 °C – 200 °C (-76 °F – 392 °F)                  |



- // Suitable for applications under extreme temperature conditions
- // Integrated option for EMC connection
- // Large clamping range due to reducer
- // No twisting of inserts and cables

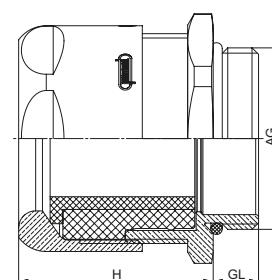

| AG         | <br>mm | GL<br>mm | H<br>mm | <br>mm<br>Dome Nut | <br>mm<br>Body | Number         |
|------------|-------------------------------------------------------------------------------------------|----------|---------|-------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------|----------------|
| M 20 x 1,5 | 7,0–14,0                                                                                  | 6        | 27      | 22                                                                                                    | 24                                                                                                | 1.751.2000.50* |
| M 20 x 1,5 | 10,0–14,0                                                                                 | 6        | 27      | 22                                                                                                    | 24                                                                                                | 1.751.2000.51  |
| M 25 x 1,5 | 11,0–18,0                                                                                 | 7        | 29      | 27                                                                                                    | 30                                                                                                | 1.751.2500.50* |
| M 25 x 1,5 | 14,5–18,0                                                                                 | 7        | 29      | 27                                                                                                    | 30                                                                                                | 1.751.2500.51  |
| M 32 x 1,5 | 16,0–25,0                                                                                 | 8        | 34      | 36                                                                                                    | 40                                                                                                | 1.751.3200.50* |
| M 32 x 1,5 | 20,5–25,0                                                                                 | 8        | 34      | 36                                                                                                    | 40                                                                                                | 1.751.3200.51  |
| M 40 x 1,5 | 21,0–32,0                                                                                 | 8        | 40      | 46                                                                                                    | 50                                                                                                | 1.751.4000.50* |
| M 40 x 1,5 | 26,5–32,0                                                                                 | 8        | 40      | 46                                                                                                    | 50                                                                                                | 1.751.4000.51  |

\* Versions with removable reducers