


EXIOS +Standard INOX

Item number 1605160250

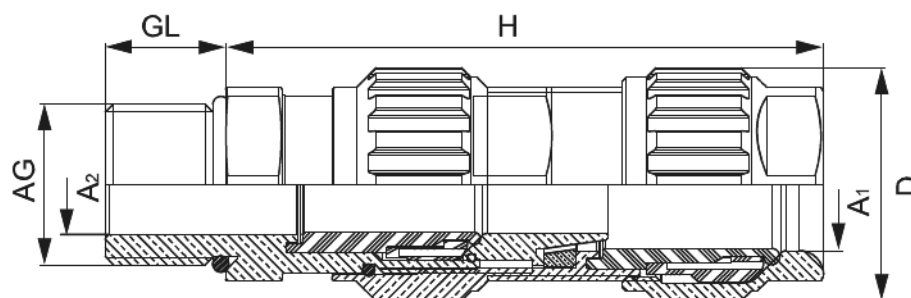

Technical data

Material	INOX 1.4404
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Armour	Metallic armour or screen
Protection class	IP 68 - 5 bar, IP 67, IP 66
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	Metric
External thread (AG)	M16 x 1,5
Size	20 - 1
A1	6 - 12 mm
A2	3 - 8.1 mm
Thread length (GL)	16 mm



ATEX

ABS



Dimensions and specifications may be changed without prior notice

www.hummel.com

EXIOS +Standard INOX

Item number 1605160250

Height (H)	69,5 mm
Wrench size (SW1/SW2)	22/22 mm
D	27 mm
Armouring clamping ring 1	- 0,7 mm
Armouring clamping ring 2	0,7 - 1,25 mm
Tightening torque	8 Nm



ATEX

ABS



Dimensions and specifications may be changed without prior notice

www.hummel.com

EXIOS +Standard INOX

Item number 1605160250

Commercial data

Packaging Unit	10
EAN code	4033878427415
Weight	0.175 kg
ETIM 7	EC000441
eCl@ss 10.1	27-14-44-34

Note:

