


EXIOS +Standard INOX

Item number 1605200252

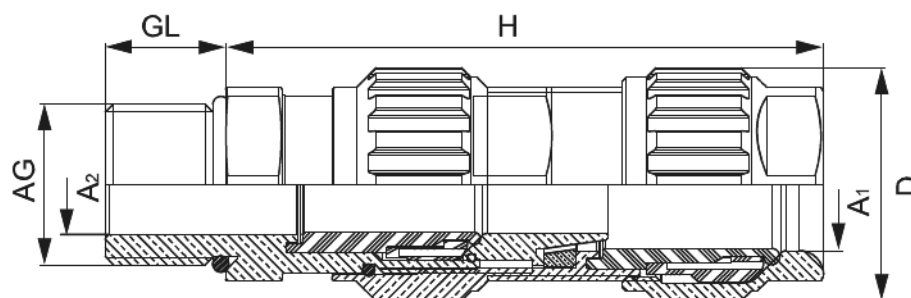

Technical data

Material	INOX 1.4404
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Armour	Metallic armour or screen
Protection class	IP 68 - 5 bar, IP 67, IP 66
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	Metric
External thread (AG)	M20 x 1,5
Size	20 - 3
A1	12.5 - 20.5 mm
A2	9 - 14 mm
Thread length (GL)	16 mm



ATEX

ABS



Dimensions and specifications may be changed without prior notice

www.hummel.com

EXIOS +Standard INOX

Item number 1605200252

Height (H)	80,5 mm
Wrench size (SW1/SW2)	30/30 mm
D	35 mm
Armouring clamping ring 1	- 0,7 mm
Armouring clamping ring 2	0,9 - 1,6 mm
Armouring clamping ring 3 (optional)	0,7 - 1,4 mm
Tightening torque	12 Nm



ATEX

ABS



Dimensions and specifications may be changed without prior notice

www.hummel.com

EXIOS +Standard INOX

Item number 1605200252

Commercial data

Packaging Unit	10
EAN code	4033878427491
Weight	0.27 kg
ETIM 7	EC000441
eCl@ss 10.1	27-14-44-34

Note:



Dimensions and specifications may be changed without prior notice



www.hummel.com