


EXIOS +Standard INOX

Item number 1605250250

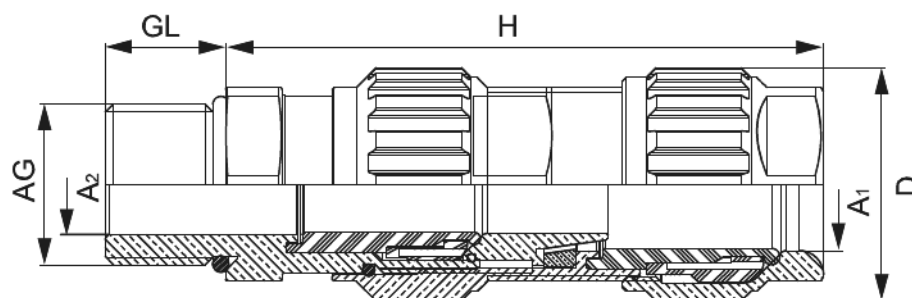

Technical data

Material	INOX 1.4404
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Armour	Metallic armour or screen
Protection class	IP 68 - 5 bar, IP 67, IP 66
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	Metric
External thread (AG)	M25 x 1,5
Size	25
A1	16.9 - 26 mm
A2	12.5 - 20.5 mm
Thread length (GL)	16 mm



ATEX

ABS



Dimensions and specifications may be changed without prior notice

www.hummel.com

EXIOS +Standard INOX

Item number 1605250250

Height (H)	91 mm
Wrench size (SW1/SW2)	36/36 mm
D	42 mm
Armouring clamping ring 1	- 1 mm
Armouring clamping ring 2	1,5 - 2,5 mm
Armouring clamping ring 3 (optional)	1 - 2 mm
Tightening torque	18 Nm



ATEX

ABS



Dimensions and specifications may be changed without prior notice

www.hummel.com

EXIOS +Standard INOX

Item number 1605250250

Commercial data

Packaging Unit	5
EAN code	4033878427576
Weight	0.39 kg
ETIM 7	EC000441
eCl@ss 10.1	27-14-44-34

Note:



Dimensions and specifications may be changed without prior notice



www.hummel.com