


EXIOS +Standard INOX

Item number 1605340270

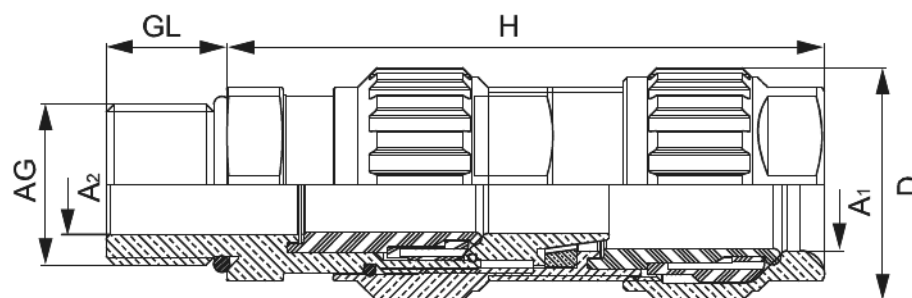

Technical data

Material	INOX 1.4404
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Armour	Metallic armour or screen
Protection class	IP 68 - 5 bar, IP 67, IP 66
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	NPT
External thread (AG)	NPT 3/4"
Size	25
A1	16.9 - 26 mm
A2	12.5 - 20.5 mm
Thread length (GL)	20,5 mm



ATEX

ABS



Dimensions and specifications may be changed without prior notice

www.hummel.com

EXIOS +Standard INOX

Item number 1605340270

Height (H)	91 mm
Wrench size (SW1/SW2)	36/36 mm
D	42 mm
Armouring clamping ring 1	- 0,7 mm
Armouring clamping ring 2	1,3 - 2 mm
Armouring clamping ring 3 (optional)	0,7 - 1,4 mm
Tightening torque	18 Nm



ATEX

ABS



Dimensions and specifications may be changed without prior notice

www.hummel.com

EXIOS +Standard INOX

Item number 1605340270

Commercial data

Packaging Unit	5
EAN code	4033878427682
Weight	0.36 kg
ETIM 7	EC000441
eCl@ss 10.1	27-14-44-34

Note:



Dimensions and specifications may be changed without prior notice



www.hummel.com