


EXIOS +A2F INOX

Item number 1608160250

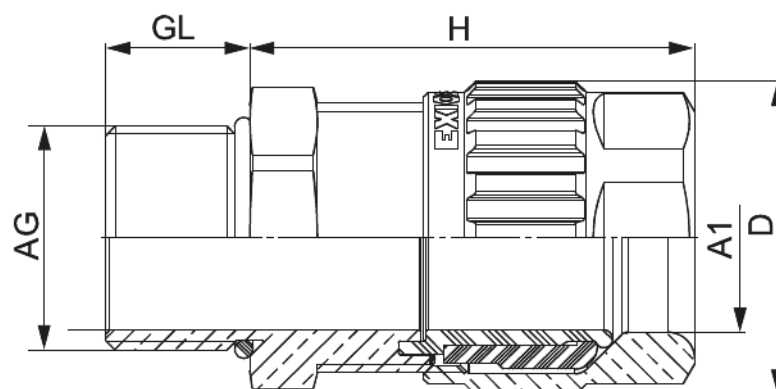

Technical data

Material	INOX 1.4404
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Protection class	IP 68 – 5 bar, IP 66, IP 68
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	Metric
External thread (AG)	M16 x 1,5
Size	20-1
A1	6 – 12 mm
Thread length (GL)	16 mm
Height (H)	35,6 mm
Wrench size (SW1/SW2)	22/22 mm

EXIOS +A2F INOX

Item number 1608160250

D	27 mm
---	-------

Tightening torque	8 Nm
-------------------	------



ATEX

ABS



kti



Dimensions and specifications may be changed without prior notice

www.hummel.com

EXIOS +A2F INOX

Item number 1608160250

Commercial data

Packaging Unit	10
EAN code	4033878428764
Weight	0.06578 kg
ETIM 7	EC000441

Note:



Dimensions and specifications may be changed without prior notice



www.hummel.com