


EXIOS +A2F INOX

Item number 1608200251

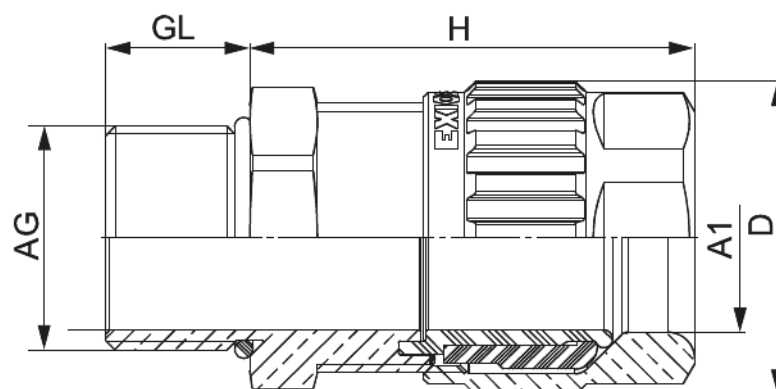

Technical data

Material	INOX 1.4404
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Protection class	IP 68 – 5 bar, IP 66, IP 68
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	Metric
External thread (AG)	M20 x 1,5
Size	20-2
A1	9 – 16 mm
Thread length (GL)	16 mm
Height (H)	39,7 mm
Wrench size (SW1/SW2)	24/24 mm

EXIOS +A2F INOX

Item number 1608200251

D	29 mm
---	-------

Tightening torque	8 Nm
-------------------	------



Dimensions and specifications may be changed without prior notice



www.hummel.com

EXIOS +A2F INOX

Item number 1608200251

Commercial data

Packaging Unit	10
EAN code	4033878428825
Weight	0.07853 kg
ETIM 7	EC000441

Note:

