


EXIOS +A2F INOX

Item number 1608200270

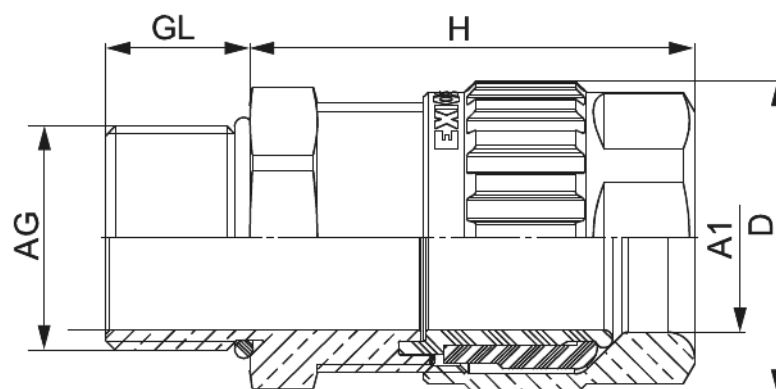

Technical data

Material	INOX 1.4404
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Protection class	IP 68 – 5 bar, IP 66, IP 68
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	NPT
External thread (AG)	NPT 2"
Size	50
A1	40 - 52.6 mm
Thread length (GL)	27 mm
Height (H)	65,4 mm
Wrench size (SW1/SW2)	65/65 mm

EXIOS +A2F INOX

Item number 1608200270

D	73 mm
Tightening torque	60 Nm



Dimensions and specifications may be changed without prior notice



www.hummel.com

EXIOS +A2F INOX

Item number 1608200270

Commercial data

Packaging Unit	1
EAN code	4033878428832
Weight	0.67 kg
ETIM 7	EC000441

Note:

