


EXIOS +A2F INOX

Item number 1608320250

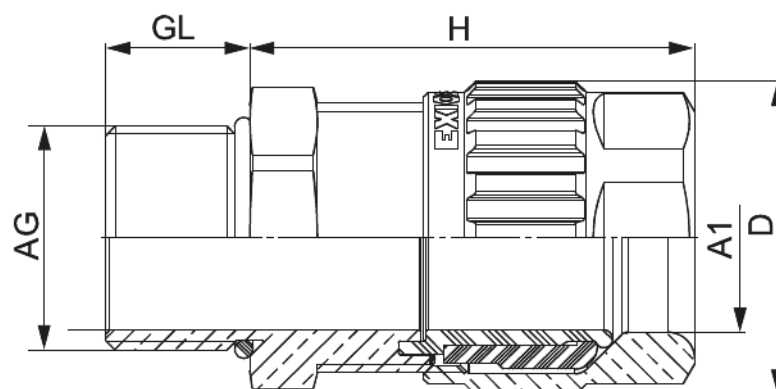

Technical data

Material	INOX 1.4404
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Protection class	IP 68 – 5 bar, IP 66, IP 68
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	Metric
External thread (AG)	M32 x 1,5
Size	25
A1	16.9 – 26 mm
Thread length (GL)	16 mm
Height (H)	47,8 mm
Wrench size (SW1/SW2)	36/36 mm

EXIOS +A2F INOX

Item number 1608320250

D	42 mm
Tightening torque	18 Nm



Dimensions and specifications may be changed without prior notice



www.hummel.com

EXIOS +A2F INOX

Item number 1608320250

Commercial data

Packaging Unit	5
EAN code	4033878428948
Weight	0.1839 kg
ETIM 7	EC000441

Note:



Dimensions and specifications may be changed without prior notice



www.hummel.com