


EXIOS +A2F INOX

Item number 1608500250

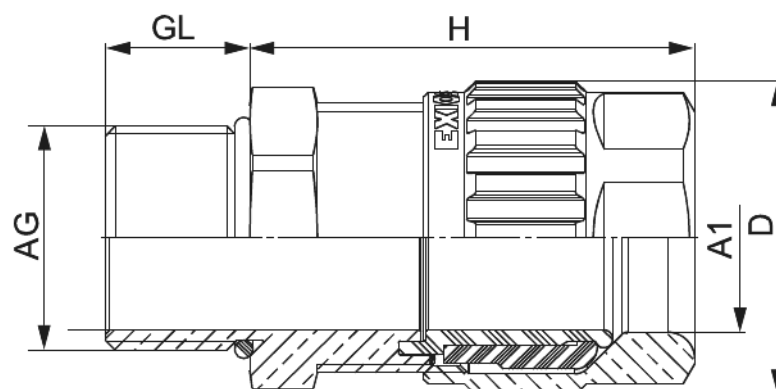

Technical data

Material	INOX 1.4404
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Protection class	IP 68 – 5 bar, IP 66, IP 68
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	Metric
External thread (AG)	M50 x 1,5
Size	40
A1	28 – 41 mm
Thread length (GL)	16 mm
Height (H)	56,8 mm
Wrench size (SW1/SW2)	55/55 mm

EXIOS +A2F INOX

Item number 1608500250

D	64 mm
Tightening torque	50 Nm



Dimensions and specifications may be changed without prior notice



www.hummel.com

EXIOS +A2F INOX

Item number 1608500250

Commercial data

Packaging Unit	1
EAN code	4033878429068
Weight	0.46918 kg
ETIM 7	EC000441

Note:

