


EXIOS +A2F INOX

Item number 1608540270

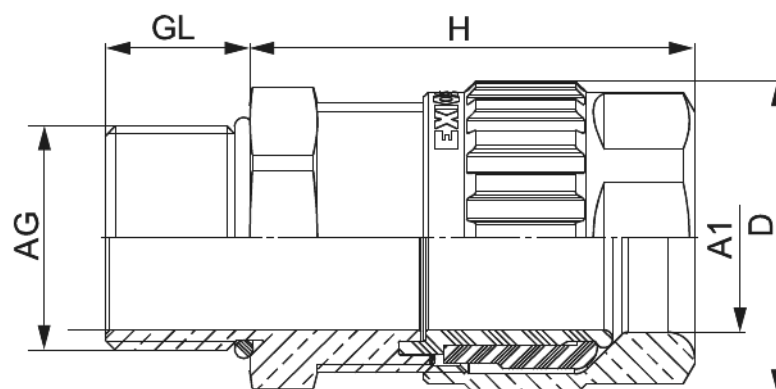

Technical data

Material	INOX 1.4404
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Protection class	IP 68 – 5 bar, IP 66, IP 68
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	NPT
External thread (AG)	NPT 1 1/4"
Size	32
A1	22 - 33 mm
Thread length (GL)	26 mm
Height (H)	51,1 mm
Wrench size (SW1/SW2)	46/46 mm

EXIOS +A2F INOX

Item number 1608540270

D	52 mm
Tightening torque	30 Nm



Dimensions and specifications may be changed without prior notice



www.hummel.com

EXIOS +A2F INOX

Item number 1608540270

Commercial data

Packaging Unit	1
EAN code	4033878429129
Weight	0.37558 kg
ETIM 7	EC000441

Note:

