


EXIOS +MZ nickel-plated brass

Item number 16Z5120370

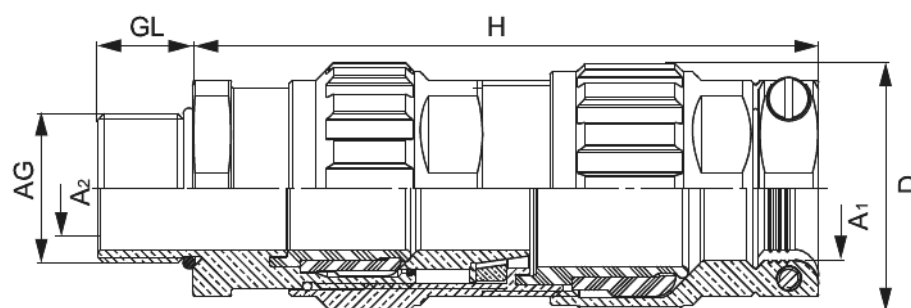

Technical data

Material	Nickel-plated brass
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Armour	Metallic armour or screen
Protection class	IP 68 - 5 bar, IP 67, IP 66
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	NPT
External thread (AG)	NPT 1/2"
Size	20 - 2
A1	9 - 13 mm
A2	6 - 12 mm
Thread length (GL)	20 mm

EXIOS +MZ nickel-plated brass

Item number 16Z5120370

Height (H)	83,8 mm
Wrench size (SW1/SW2)	24/24 mm
D	29 mm
Armouring clamping ring 1	- 0,7 mm
Armouring clamping ring 2	0,7 - 1,25 mm
Armouring clamping ring 3 (optional)	- mm
Tightening torque	8 Nm

EXIOS +MZ nickel-plated brass

Item number 16Z5120370

Commercial data

Packaging Unit	10
EAN code	4033878001455
Weight	0.20453 kg
ETIM 7	EC000441
eCl@ss 10.1	27-14-44-34

Note:



Dimensions and specifications may be changed without prior notice



www.hummel.com