


EXIOS +MZ nickel-plated brass

Item number 16Z5120371

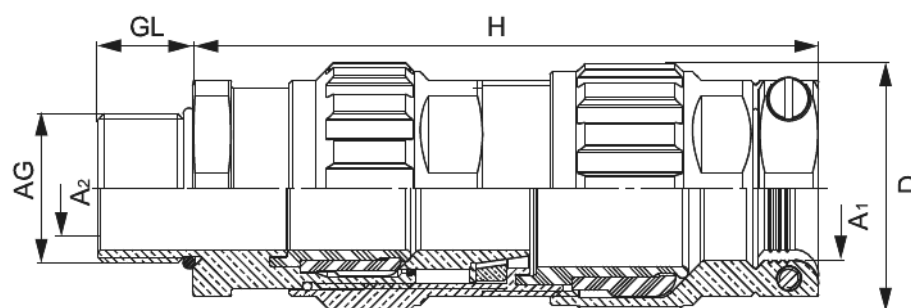

Technical data

Material	Nickel-plated brass
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Armour	Metallic armour or screen
Protection class	IP 68 - 5 bar, IP 67, IP 66
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	NPT
External thread (AG)	NPT 1/2"
Size	20 - 3
A1	12.5 - 17.5 mm
A2	9 - 14 mm
Thread length (GL)	20 mm



ATEX

ABS



kti



Dimensions and specifications may be changed without prior notice

www.hummel.com

EXIOS +MZ nickel-plated brass

Item number 16Z5120371

Height (H)	91,5 mm
Wrench size (SW1/SW2)	30/30 mm
D	35 mm
Armouring clamping ring 1	- 0,7 mm
Armouring clamping ring 2	0,7 - 1,4 mm
Armouring clamping ring 3 (optional)	- mm
Tightening torque	12 Nm

EXIOS +MZ nickel-plated brass

Item number 16Z5120371

Commercial data

Packaging Unit	10
EAN code	4033878454145
Weight	0.33123 kg
ETIM 7	EC000441
eCl@ss 10.1	27-14-44-34

Note:



Dimensions and specifications may be changed without prior notice



www.hummel.com