


EXIOS +MZ nickel-plated brass

Item number 16Z5500350

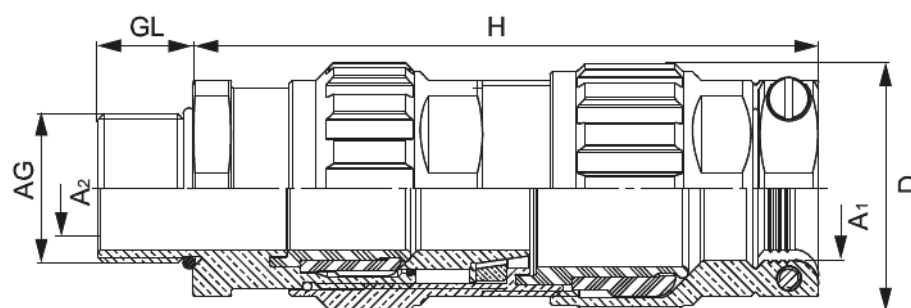

Technical data

Material	Nickel-plated brass
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Armour	Metallic armour or screen
Protection class	IP 68 - 5 bar, IP 67, IP 66
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	Metric
External thread (AG)	M50 x 1,5
Size	50
A1	36 - 49 mm
A2	28.9 - 44.4 mm
Thread length (GL)	16 mm



ATEX

ABS



kti



Dimensions and specifications may be changed without prior notice

www.hummel.com

EXIOS +MZ nickel-plated brass

Item number 16Z5500350

Height (H)	144,5 mm
Wrench size (SW1/SW2)	65/65 mm
D	73 mm
Armouring clamping ring 1	- 1 mm
Armouring clamping ring 2	1,5 - 2,5 mm
Armouring clamping ring 3 (optional)	1 - 2 mm
Tightening torque	60 Nm

EXIOS +MZ nickel-plated brass

Item number 16Z5500350

Commercial data

Packaging Unit	1
EAN code	4033878001301
ETIM 7	EC000441
eCl@ss 10.1	27-14-44-34

Note:

