




DIN 7972 C

~ISO 1482

450 HV

Standard withdrawn

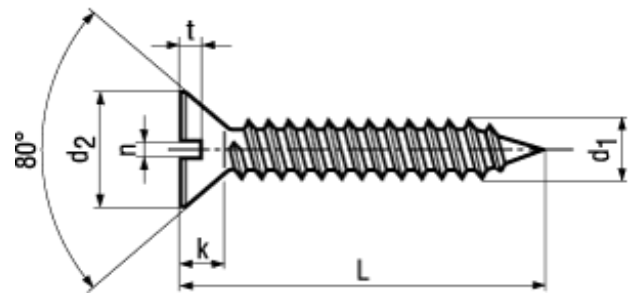

BN 990

Slotted flat countersunk head tapping screws

with cone end type C

Steel case-hardened 450 HV

zinc plated blue

- ~UNI 6952 AB
- ~ČSN 021236

**ISO 4042**

Quenched and tempered fasteners ≥ 360 HV and tempered case-hardened fasteners with electroplated coatings: Susceptible to hydrogen embrittlement! Further notice to residual risks can be found in the introduction section.

[3D Cadenas](#)

Countersunk must be designed according to the corresponding standard!

Article#	d ₁	d ₂ max.	k~	n	t min.	L
1372971	ST 2,2	4,3	1,3	0,6	0,4	6,5
1372998						9,5
1373005						13
1373013						16
1373048	ST 2,9	5,5	1,7	0,8	0,5	6,5
1373056						9,5
1373064						13
1373072						16
1373080						19
1373102						25
1373110	ST 3,5	6,8	2,1	1	0,6	9,5
1373129						13
1373137						16
1373145						19
1373218	(ST 3,9)	7,5	2,3	1	0,7	9,5
1373226						13
1373234						16
1373242						19
1373269						25
1373293	ST 4,2	8,1	2,5	1,2	0,75	9,5
1373307						13
1373315						16
1373323						19
1373358						25