




DIN 934

~ISO 4032

8

Standard withdrawn

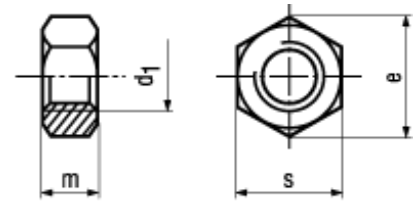

BN 117

Hex nuts ~0,8d

Steel 8

zinc plated blue

- ~UNI 5588
- ~ČSN 021401

[3D Cadenas](#)

M10; M12; M14; M22: wrench size according to ISO on request

Article#	d ₁	e min.	s	m max.	
1874659	M3	6,01	5,5	2,4	100
1874667					1000
1089536					10000
1874675	(M3,5)	6,58	6	2,8	100
1874683					1000
1874691	M4	7,66	7	3,2	100
1874705					1000
1089552					5000
1874713	M5	8,79	8	4	100
1874721					1000
1089560					5000
1874748	M6	11,05	10	5	100
1874756					1000
1089579					5000
1874764	(M7)	12,12	11	5,5	100
1089587					1000
1874772	M8	14,38	13	6,5	100
1089595					1000
1874780	M10	18,9	17	8	100
1089609					500
1874799	M12	21,1	19	10	100
1089617					500
1874802	(M14)	24,49	22	11	50
1089625					200
1874810	M16	26,75	24	13	50
1089633					200

M10; M12; M14; M22: wrench size according to ISO on request

Article#	d ₁	e min.	s	m max.	
1089641	(M18)	29,56	27	15	50
1874829	M20	32,95	30	16	50
1089668					100
1089676	(M22)	35,03	32	18	50
1089684	M24	39,55	36	19	50
1089692	(M27)	45,2	41	22	25
1089706	M30	50,85	46	24	25
1089714	(M33)	55,37	50	26	10
1089722	M36	60,79	55	29	10
5510541	(M39)	66,44	60	31	1
5503976	M42	71,3	65	34	1
5523246	(M45)	76,95	70	36	1
5514436	M48	82,6	75	38	1