




DIN 551

Standard withdrawn

ISO 4766

14 H / 22 H

At manufacturer's option

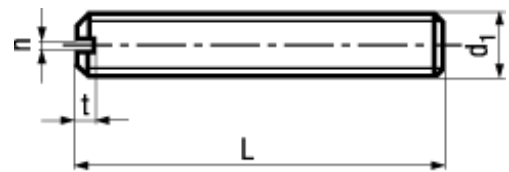

BN 427

Slotted set screws

with flat point, chamfered

Steel 14 H / 22 H

zinc plated blue

- ~UNI 6113
- ~CSN 021181



Set screws are not intended to be tensile-loaded.

M16: not included in DIN 551 and ISO 4766

Article#	d ₁	n	t min.	L
1177273	M2	0,25	0,64	2
1177281				3
1177303				4
1177311				5
1177338				6
1177346				8
1177354				10
1177362				12
1435736	M2,5	0,4	0,72	2
1177478				3
1177486				4
1177494				5
1177508				6
1177516				8
1177524				10
1177532				12
1177613	M3	0,4	0,8	3
1177621				4
1177648				5
1177656				6
1177664				8
1177672				10
1177680				12
1177699				(14)

M16: not included in DIN 551 and ISO 4766

Article#	d ₁	n	t min.	L
1177702	M3	0,4	0,8	16
1177710				(18)
1177729				20
1177737				25
1177745				30
1098810				40
1445308	(M3,5)	0,5	0,96	4
1445316				5
1445324				6
1445332				8
1445340				10
1445359				12
1177753	M4	0,6	1,12	3
1177761				4
1177788				5
1177796				6
1177818				8
1177826				10
1177834				12
1177842				(14)
1177850				16
1177869				(18)
1177877				20
1435795				(22)
1177885				25
1177893				30
1435809				35
1435817				40
1098829				50
1422960				60
1177915	M5	0,8	1,28	4
1177923				5
1177931				6
1177958				8
1177966				10
1177974				12
1177982				(14)
1177990				16
1178008				(18)
1178016				20
1435825				(22)

M16: not included in DIN 551 and ISO 4766

Article#	d ₁	n	t min.	L
1178024	M5	0,8	1,28	25
1178032				30
1435833				35
1435841				40
1098667				50
1070762				60
1422987				70
1422995				80
1178040	M6	1	1,6	4
1178059				5
1178067				6
1178075				8
1178083				10
1178091				12
1178105				(14)
1178113				16
1178121				(18)
1178148				20
1435868				(22)
1178156				25
1178164				30
1178172				35
1178180				40
1435876				45
1435884				50
1435892				60
1423002				70
1423010				80
1423029				90
1423037				100
1178199	M8	1,2	2	6
1178202				8
1178210				10
1178229				12
1178245				16
1178253				20
1435906				(22)
1178261				25
1178288				30
1178296				35
1178318				40

M16: not included in DIN 551 and ISO 4766

Article#	d ₁	n	t min.	L
1178326	M8	1,2	2	45
1178334				50
1435914				60
1423045				70
1423053				80
1423061				90
1070878				100
1435922	M10	1,6	2,4	6
1178342				8
1178350				10
1178369				12
1178385				16
1178407				20
1435930				(22)
1178415				25
1178423				30
1178431				35
1178458				40
1178466				45
1178474				50
1435949				60
1435957				70
1070886				80
1423088				90
1423096				100
1435965	M12	2	2,8	8
1435973				10
1435981				12
1436015				16
1178482				20
1178490				25
1178504				30
1436058				35
1178512				40
1436066				45
1178520				50
1178539				60
1070908				70
1070916				80
1070932				90
1423118				100

M16: not included in DIN 551 and ISO 4766

Article#	d ₁	n	t min.	L
1436074	M16	2,5	4	16
1436082				20
1436090				25
1436104				30
1436112				35
1436120				40
1436139				50
1436147				60