


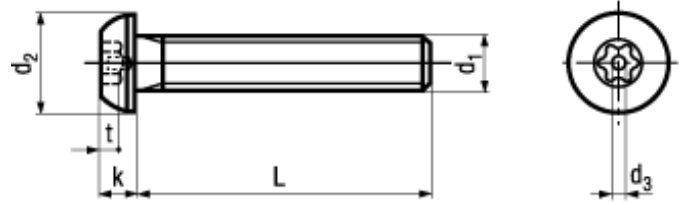

~ISO 7380-1

**BN 33021****Hexalobular (6 Lobe) socket tamper proof**

button head cap screws with center pin

Stainless steel A2

Article#	d ₁	d ₂ max.	k max.		t min.	d ₃ max.	L
5813240	M4	7,6	2,2	X20	1,1	1,4	8
5813250							10
5813260							12
5813270							16
5813280	M5	9,5	2,75	X25	1,3	1,8	10
5813290							12
5813300							16
5813310							20
5813320	M6	10,5	3,3	X30	1,7	2,3	10
5813330							12
5813340							16
5813350							20
5813360							25