


BN 2797

Serrated hex flange head cap screws

Steel 100

black

 [3D Cadenas](#)

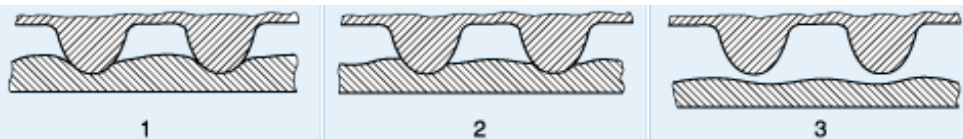

-  1. Tightening: surface penetration
- 2. Loosening: shallow corrugation
- 3. After loosening: slightly corrugated surface

Article#	d ₁	d ₂ max.	k	s	L
1480405	M5	11,2	4,3	8	10
1480413					12
1480421					(14)
1480448					16
1480456	M6	14,2	5,5	10	10
1480464					12
1480472					(14)
1480480					16
1480499					20
1480502					25
1480510	M8	18,2	7	13	12
1480529					(14)
1480537					16
1480545					20
1480553					25
1480561					30
1480588					40
1480596	M10	21	8,5	15	16
1480626					20

Article#	d ₁	d ₂ max.	k	s	L
1480642	M10	21	8,5	15	25
1480650					30
1480669	M12	24	10	17	20
1480677					25
1480685					30
1480693					35
1480707					40
1480715	M16	31	14	22	25
1480723					30
1480731					35
1480758					40
1480766					45
1480774					50
1480782					55
1480790					60
1480804					70