




DIN 7984

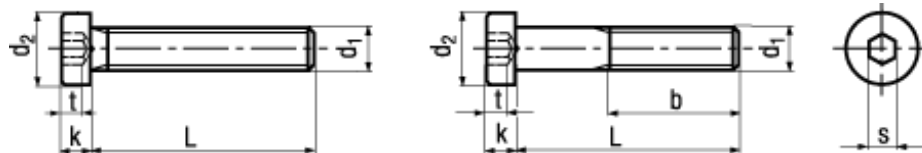

BN 2844

Hex socket head cap screws

with low head, partially / fully threaded

Stainless steel A2

- ~UNI 9327
- Tensile strength min. 600 N/mm²
- Proof stress 0,2% min. 450 N/mm²

b: the partially threaded version can not always be guaranteed

Article#	d ₁	d ₂	k	s	t	b	L
1256556	M3	5,5	2	2	1,5	-	5
1256580							6
1568736							8
1489380							10
1489399							12
1489402							16
1489410						12	20
1489429							25
1568744	M4	7	2,8	2,5	2,3	-	6
1568752							8
1489437							10
1489445							12
1489453							16
1489461							20
1489488						14	25
1489496							30
1568760	M5	8,5	3,5	3	2,7	-	8
1489518							10
1489526							12
1489534							16
1489542							20
1489550							25
1489569						16	30
1489577							35
1489585							40
1568779	M6	10	4	4	3	-	8
1568787							10

b: the partially threaded version can not always be guaranteed

Article#	d ₁	d ₂	k	s	t	b	L
1489593	M6	10	4	4	3	-	12
1489607							16
1489615							20
1489623							25
1489631						18	30
1489658							35
1489666							40
1489674							45
1489682							50
1489690							60
1568795	M8	13	5	5	3,8	-	10
1568809							12
1489704							16
1489712							20
1489720							25
1489739							30
1489747						22	35
1489755							40
1489763							45
1489771							50
1489798							60
5519085							70
1568825	M10	16	6	7	4,5	-	16
1489801							20
1489828							25
1489836							30
1489844							35
1489852						26	40
1489860							45
1489879							50
1489887							60
1489895							70
1489909							80
1568833	M12	18	7	8	5	-	20
1568841							25
1568876							30
1568884							35
1568892							40
1568914						30	50