




SN 213307

~ISO 7048

Standard withdrawn

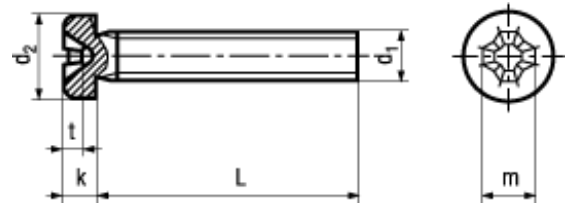

BN 2845

Phillips cheese head machine screws

form H

Stainless steel A2



All lengths fully threaded

Article#	d ₁	d ₂ max.	k max.		m~	t min.	t max.	L
1488910	M2	3,8	1,4	1	2,3	0,9	1,1	3
1488929								4
1488937								5
1488945								6
1488953								8
1488961								10
1488988								12
1488996								16
1489003	M2,5	4,5	1,8	1	2,7	1,2	1,62	4
1489011								5
1489038								6
1489046								8
1489054								10
1489062								12
1489070								16
1489089	M3	5,5	2	2	3,5	0,86	1,43	4
1489097								5
1489100								6
1489119								8
1489127								10
1489135								12
1489143								(14)
1489151								16
1489178								20
1489186	M4	7	2,6	2	4,1	1,45	2,03	5
1489194								6

Article#	d ₁	d ₂ max.	k max.		m~	t min.	t max.	L
1489208	M4	7	2,6	2	4,1	1,45	2,03	8
1489216								10
1489224								12
1489232								(14)
1489240								16
1489259								20
1489267	M5	8,5	3,3	2	4,8	2,14	2,73	6
1489275								8
1489283								10
1489291								12
1489305								16
1489313								20
1489321	M6	10	3,9	3	6,2	2,25	2,86	8
1489348								10
1489356								12
1489364								16
1489372								20