




8150J-8160J

Precision Diagonal Cutters with Oval Cutting or Stripping Head & ESD Safe Handle



PRODUCT DETAILS

- 80 Series precision diagonal and stripping cutter
- ESD safe mono-material handles with return spring
- Micro-bevel cut
- The cutting capacity given is for copper wire
- Suitable for cutting Cu
- High performance alloyed steel
- Phosphate finish
- Numerically controlled machine grinding guarantees edge angle accuracy & contact, increases the tools reliability & consistency
- Precision induction hardened edges 63-65 HRC
- Screw joint that minimizes friction & maximizes alignment of cutting edges
- Ideal for wire harness work & standard printed circuit board assembly
- Also valid for stripping

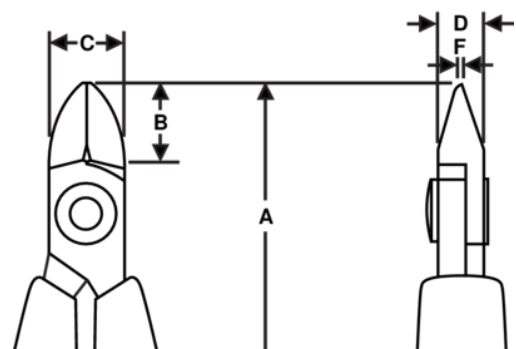

PRODUCT ATTRIBUTES

Product: 8150 J

	Oval		M	A	112.5 mm
A	4.43 in	B	13 mm	B	0,51 in
C	12,5 mm	C	0.50 in	D	6 mm
D	0,24 inch	F	1,2 mm	F	0,05 in
	Max 0.5 mm		Max 0.02 in		Micro-Bevel®
	50 g	Ω	Dissipative		

Product: 8160 J

	Oval		L	A	125.0 mm
A	4.92 in	B	16 mm	B	0,62 in
C	16 mm	C	0.63 in	D	8 mm
D	0,31 inch	F	1,6 mm	F	0,06 in
	Max 0.5 mm		Max 0.02 in		Micro-Bevel®
	87 g	Ω	Dissipative		