


Data sheet Product SLV W 4 080 20 G

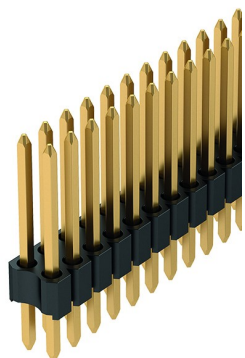


PCB connectors>Male headers

- two rows 4-72 contacts
- grid spacing 1.27 x 1.27 mm

Features

grid:	1.27 mm
no. of contacts:	20
contact material:	CuZn-alloy
surface of contact:	gold-plated
surface contact / contact sleeve:	• Ni+$\geq 0.2\mu\text{m}$ Au • Ni+4...6μm Sn
version:	standard
volume resistance:	$\leq 5\text{ m}\Omega$
nominal current:	1.5 A
nominal voltage:	125 V AC
test voltage:	300 V
insulating body material:	PA 4.6. GF
temperature range:	• -40°C... +163°C • (260°C/10 s)
class of inflammability:	UL 94 V-0
specific insulation resistance:	$>10^7\ \Omega\cdot\text{m}$
connection type:	THT (soldering)
reflow solderable:	yes

Technical Drawing

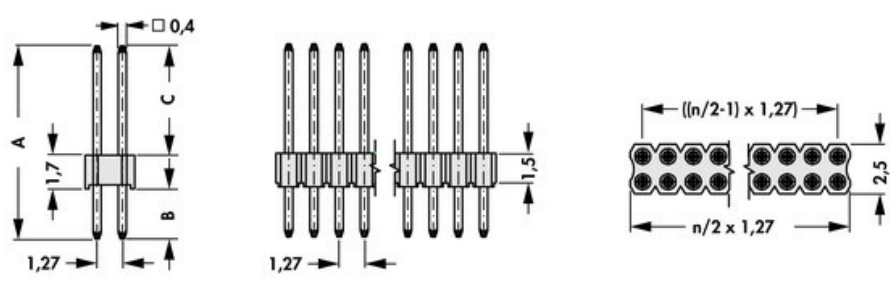	
A:	12.2 mm
B:	2.5 mm
C:	8 mm