

Fittings for FlexiGuard spiral-reinforced PVC Conduits

FG straight fitting with swivel thread, IP54

Straight swivel external thread.

Fulfils IP54 with FlexiGuard FG conduits.


Features and benefits

- One piece, easy fit
- Swivel thread
- Vibration and tension resistant
- Large bore size
- Inner ferrule protects cables
- Good resistance to chemicals
- Good resistance to UV and ozone



FG conduit fitting.

MATERIAL	Polypropylene (PP)
Operating Temperature	-35 °C to +80 °C
Flammability	UL94 V2

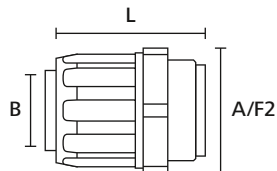

FlexiGuard fitting, straight with swivel thread



TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Length (L)	A/F Thread (A/F2)	Colour	Pack Cont.	Article-No.
FG14-M16	14	M16	8.8	42.0	20	Grey (GY)	10 pcs.	167-00530
FG14-PG9	14	PG9	8.8	42.0	20	Grey (GY)	10 pcs.	167-00510
FG17-M20	17	M20	11.1	45.5	24	Grey (GY)	10 pcs.	167-00531
FG17-PG11	17	PG11	11.1	45.5	24	Grey (GY)	10 pcs.	167-00511
FG19-PG13	19	PG13.5	13.0	47.5	27	Grey (GY)	10 pcs.	167-00512
FG21-M25	21	M25	14.8	49.8	30	Grey (GY)	10 pcs.	167-00533
FG21-PG16	21	PG16	14.8	49.8	30	Grey (GY)	10 pcs.	167-00513
FG27-M32	27	M32	19.4	52.0	36	Grey (GY)	10 pcs.	167-00534
FG27-PG21	27	PG21	19.4	52.0	36	Grey (GY)	10 pcs.	167-00514
FG36-M40	36	M40	27.9	55.0	46	Grey (GY)	10 pcs.	167-00535
FG36-PG29	36	PG29	27.9	55.0	46	Grey (GY)	10 pcs.	167-00515
FG45-M50	45	M50	35.6	58.0	55	Grey (GY)	10 pcs.	167-00536
FG45-PG36	45	PG36	35.6	58.0	55	Grey (GY)	10 pcs.	167-00516
FG56-M63	56	M63	45.9	60.5	65	Grey (GY)	10 pcs.	167-00537
FG56-PG48	56	PG48	45.9	60.5	65	Grey (GY)	10 pcs.	167-00517

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.