



HelaGuard Accessories

• ACP Couplers

Internally threaded, nickel plated brass.

Features and Benefits

- Can be used to convert from external to internal thread




HelaGuard ACP Couplers.

MATERIAL	Nickel Plated Brass (NPB)
Operating Temperature	-100 °C to +300 °C

HF ✓

RoHS ✓

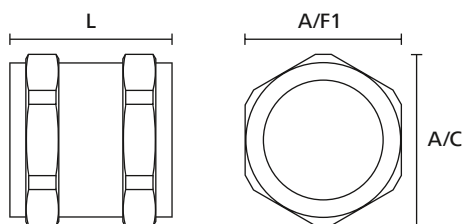

HelaGuard threaded coupler

TYPE	Thread Size	Length (L)	A/F Body (A/F1)	Across Corners (A/C)	Pack Cont.	Colour	Article-No.
ACP-M16	M16	22.5	20	22	10 pcs.	Metal (ML)	166-50400
ACP-M20	M20	25.0	24	27	10 pcs.	Metal (ML)	166-50401
ACP-M25	M25	30.0	29	32	10 pcs.	Metal (ML)	166-50402
ACP-M32	M32	32.5	35	39	10 pcs.	Metal (ML)	166-50403
ACP-M40	M40	34.0	48	53	2 pcs.	Metal (ML)	166-50404
ACP-M50	M50	38.0	58	64	1 pcs.	Metal (ML)	166-50405
ACP-M63	M63	45.0	70	77	1 pcs.	Metal (ML)	166-50406
ACP-M75	M75	45.0	84	93	1 pcs.	Metal (ML)	166-50407

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.