



HelaGuard Accessories

• AFCP Clip for Rigid Conduits

Features and Benefits

- Easy and quick assembly with metallic conduits
- Lid is integrated
- Hole for fastening with screw
- Can be used in C-shaped DIN rails




HelaGuard AFCP Conduit Clip.


MATERIAL	Polyamide 6.6 (PA66)
Operating Temperature	-50 °C to +135 °C
Flammability	UL94 V2

HF ✓

RoHS ✓

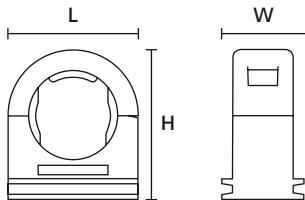

HelaGuard conduit clip, side views

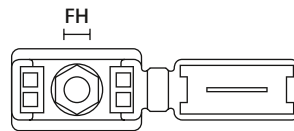

HelaGuard conduit clip, top view

TYPE	Nominal Ø	Height (H)	Width (W)	Length (L)	Hole Ø (FH)	Pack Cont.	Colour	Article-No.
AFCP16	16	30	12	26	M5	10 pcs.	Black (BK)	166-50700
AFCP20	20	36	15	32	M6	10 pcs.	Black (BK)	166-50701
AFCP25	25	45	15	41	M6	10 pcs.	Black (BK)	166-50702
AFCP33	32	51	15	48	M6	10 pcs.	Black (BK)	166-50703

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.



CAD download