


Technical Datasheet **tasker® TSK 1148 – 2x0,20 mm²** Flat Miniature Cable in silver plated copper

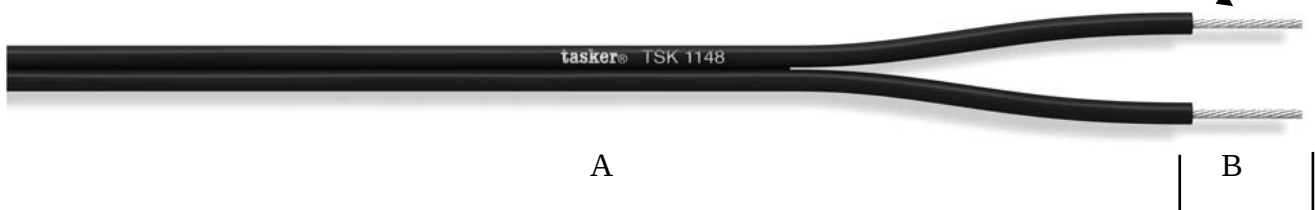

CATEGORY Miniature Cable (See Audio Catalogue)
APPLICATIONS Speaker and Home Theatre installation

- A:** Black PVC Sheath.
 Outer cable Dimension 1,40x2,80 (±0,10) mm.
- B:** O.F.C. Silver Plated Copper + Kevlar stranded formation 7x0,20 mm.
 Nom. Cross section 2x0,20 mm².

MARKING **tasker®** TSK1148 2x0.20 mm² – SILVER PLATED O.F.C. + KEVLAR MICRO AUDIO CABLE.

CUSTOM PRODUCTION This product may be custom produced also in L.S.Z.H. polymer, PE, PUR.

Cable Properties

Conductor Resistance	80 Ω/Km
Max Rated Voltage	30 V
Operative Temperature	-15/+70°C

USE	X	Indoor	Interno Edificio
Impiego		Outdoor Limited	Esterno Limitato
		Outdoor	Esterno
		Outdoor Direct Burial	Esterno Interrato

INSTALLATION	X	Fixed	Fissa
Posa	X	Restricted Mobile	Mobile Limitata
		Mobile	Mobile
		Mobile in Drag Chain	Mobile in Catena

INFORMATION	X	RoHS2 Compliant
Informazioni	X	Ver. A / 26.05.17