


FirestoP® Technical Datasheet

tasker® C296 - 4x0,22 + 2x0,50mm² - Alarm Cable

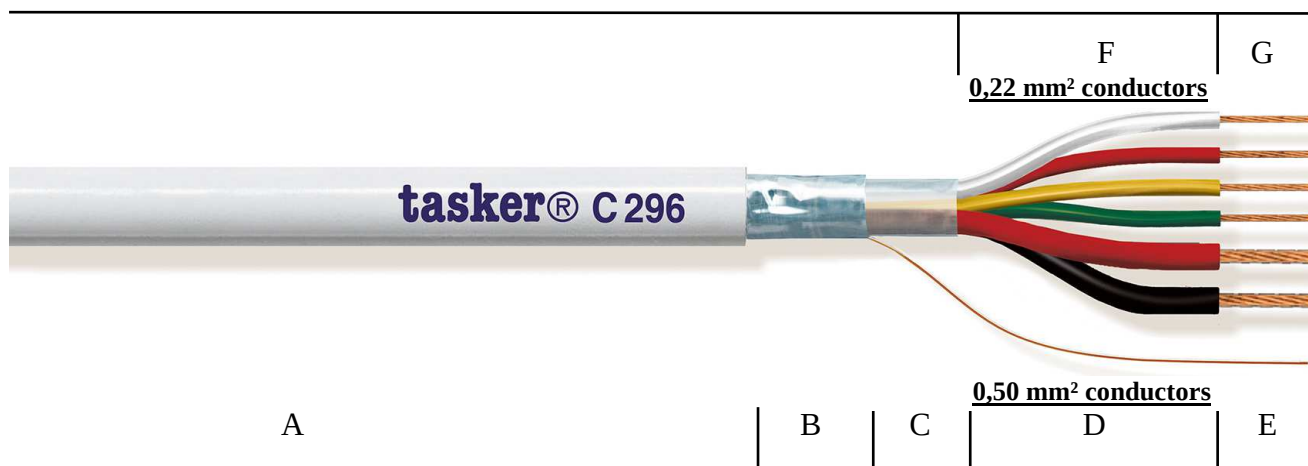

CATEGORY Alarm Cable (See Data Network Catalogue).

APPLICATIONS Alarm Systems and Electronics.

- A:** White Soft **Flame Retardant PVC** sheath. RAL 9003.
Outer Diam. Ø 4,80 (±0,20) mm.
- B:** Shielding with Aluminum polyester tape covering 100%
+ Drain Wire in O.F.C. red copper.
- C:** The six conductors are stranded together with polyester based tape.

2x0,50 mm² conductors

- D:** Insulation with PVC. Diam. Ø 1,50 (±0,20) mm. Core colors: Red, Black.
- E:** Stranded formation of 16x0,20 mm in O.F.C. Red Copper .
Nom. Cross section 2x0,50 mm².

4x 0,22 mm² conductors

- F:** Insulation with PVC. Diam. Ø 1,00 (±0,20) mm.
Core colors: White, Red, Yellow and Green.
- G:** Stranded formation of 7x0,20 mm in O.F.C. Red Copper
Nom. Cross section 4x0,22 mm²



MILAN S.r.l. a socio unico

Head Office – Export department:

Viale Europa, 74
20090 Cusago (MI) Italy
T. +39 02 9039.4556-4158
F. +39 02 9039.4551
www.taskercables.com

Ufficio Commerciale e Centro Distribuzione

Viale Europa 72 Strada F12
20090 Cusago (MI) Italy
T. +39 02 9039.0037-0059
F. +39 02 9039.0049
www.tasker.it

MARKING

tasker® Shielded Alarm Systems cable - FirestoP® Made in Italy

**CUSTOM
PRODUCTION**

This product may be custom produced also in **L.S.Z.H., PE, PUR**, with or without Metallic Armor.

Cable Properties

Conductor 0,22 mm² Resistance	79,15 Ω/Km
Conductor 0,50 mm² Resistance	38,00 Ω/Km
Max Rated Voltage	49 V
Operative Temperature	-20/+70°C

USE	X	Indoor	Interno Edificio
Impiego		Outdoor Limited	Esterno Limitato
		Outdoor	Esterno
		Outdoor Direct Burial	Esterno Interrato

INSTALLATION	X	Fixed	Fissa
Posa	X	Restricted Mobile	Mobile Limitata
		Mobile	Mobile
		Mobile in Drag Chain	Mobile in Catena

INFORMATION	X	RoHS3 Compliant
Informazioni	X	Ver. B / 26.05.19