


Technical Datasheet

tasker® C215 – 8x0,25 mm² - LiYCY Cable

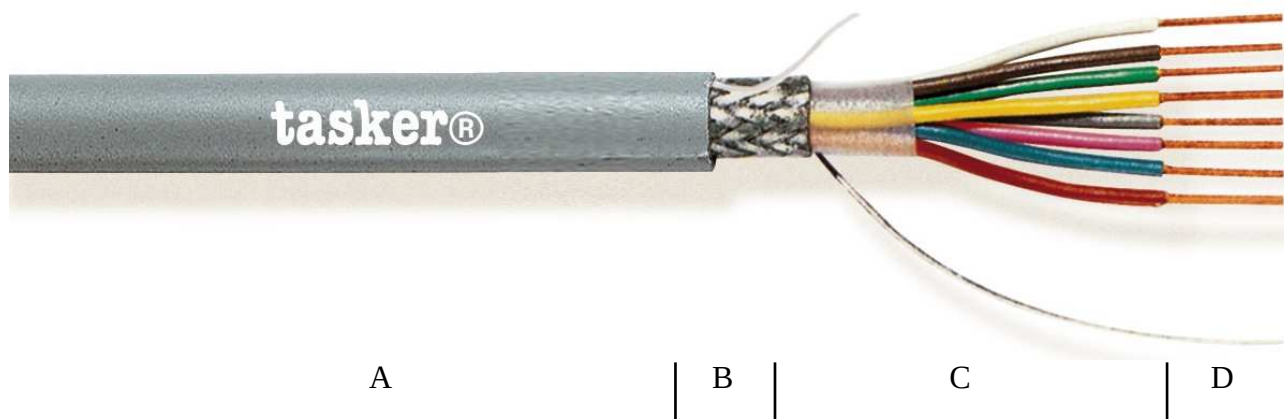

CATEGORY Shielded Cable (See Data Network Catalogue)
APPLICATIONS Data transmission and electronics.

- A:** Grey Soft **PVC** Sheath.
 Outer cable Ø: 7,40 (±0,10) mm.
B: Braided Shielding in O.F.C. Tinned Copper, covering 85% + Drain Wire.
C: Cores Insulation with Soft **PVC**– DIN 47100 Standards.
 Color Code: White, Brown, Green, Yellow, Grey, Pink, Blue, Red.
 Diam. Ø 1,30 (±0,10) mm. Stranded with waste filler between conductors and wrapped with Mylar Tape.
D: Stranded O.F.C. Red Copper formation 14x0,15 mm.
 Nom. Cross section 8x0,25 mm².

MARKING **tasker®** C215 LiYCY 8x0,25 – 23 AWG Low Voltage Computer Cable made in Italy

CUSTOM PRODUCTION This product may be custom produced also in **L.S.Z.H.** polymer, **PE**, **PUR**, with or without Metallic Armor.

Cable Properties

Conductor Resistance	75,85 Ω/Km
Capacity Core/Core	80 pF/mt
Capacity Core/Shield	150 pF/mt
Max Rated Voltage	49 V
Operative Temperature	-15/+70°C

USE	X	Indoor	Interno Edificio	INSTALLATION	X	Fixed	Fissa	INFORMATION	X	RoHS2 Compliant
Impiego		Outdoor Limited	Esterno Limitato	Posa	X	Flexible Limited	Flessibilità limitata	Informazioni	X	Ver. A / 08.07.2016
		Outdoor	Esterno			Dynamic (Drag Chain)	Mobile in Catena			
		Outdoor Direct Burial	Esterno Interrato			Dynamic (Torsion)	Mobile in Torsione			