



MILAN S.r.l. a socio unico

Head Office – Export department:

Viale Europa, 74
20090 Cusago (MI) Italy
T. +39 02 9039.4556-4158
F. +39 02 9039.4551
www.taskercables.com

Ufficio Commerciale e Centro Distribuzione

Viale Europa 72 Strada F12
20090 Cusago (MI) Italy
T. +39 02 9039.0037-0059
F. +39 02 9039.0049
www.tasker.it

✓
RoHS₂
2002/95/EC
2011/65/UE




Firestop®

Technical Datasheet

tasker® C8050 CPR – 8x0,50 mm²

Braided Shielded Cable

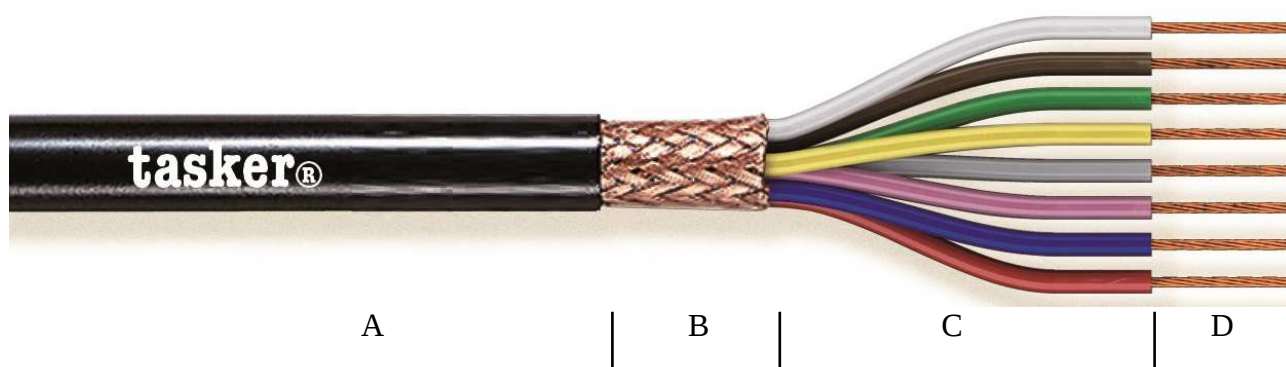

CATEGORY

Braided Conductor Shielded Cable (See Data Network Catalogue)

APPLICATIONS

Data transmission and Electronics

- A:** Black **Flame Retardant PVC** sheath.
Outer cable diam. Ø 8,60 (±0,20) mm.
- B:** Braided Shielding O.F.C. Red Copper covering 85%.
- C:** Cores Insulation with **Flame Retardant PVC**.
Core color code with DIN 47100 Standards.
Diam. Ø 1,90 (±0,20) mm.
- D:** Stranded O.F.C. Red Copper formation 16x0,20 mm.
Nom. Cross section 8x0,50 mm².

MARKING

tasker® C8050 CPR 8x0,50 mm² O.F.C. - IMQ 0051-CPR-0966 – 2017 – Eca –
BRAIDED SHIELDED CABLE - Firestop® - Made Italy

Cable Properties

Conductor Resistance	38,00 Ω/Km
Capacity Core/Core	110 pF/mt
Capacity Core/Shield	210 pF/mt
Max Rated Voltage	49 V
Operative Temperature	-20/+70°C

USE	X	Indoor	Interno Edificio
Impiego	X	Outdoor Limited	Esterno Limitato
		Outdoor	Esterno
		Outdoor Direct Burial	Esterno Interrato

INSTALLATION	X	Fixed	Fissa
Posa	X	Restricted Mobile	Mobile Limitata
		Mobile	Mobile
		Mobile in Drag Chain	Mobile in Catena

INFORMATION	X	RoHS2 Compliant
Informazioni	X	Ver. A / 26.05.17