




DVI(24+1) Male to Male Cable

DVI HD Cable

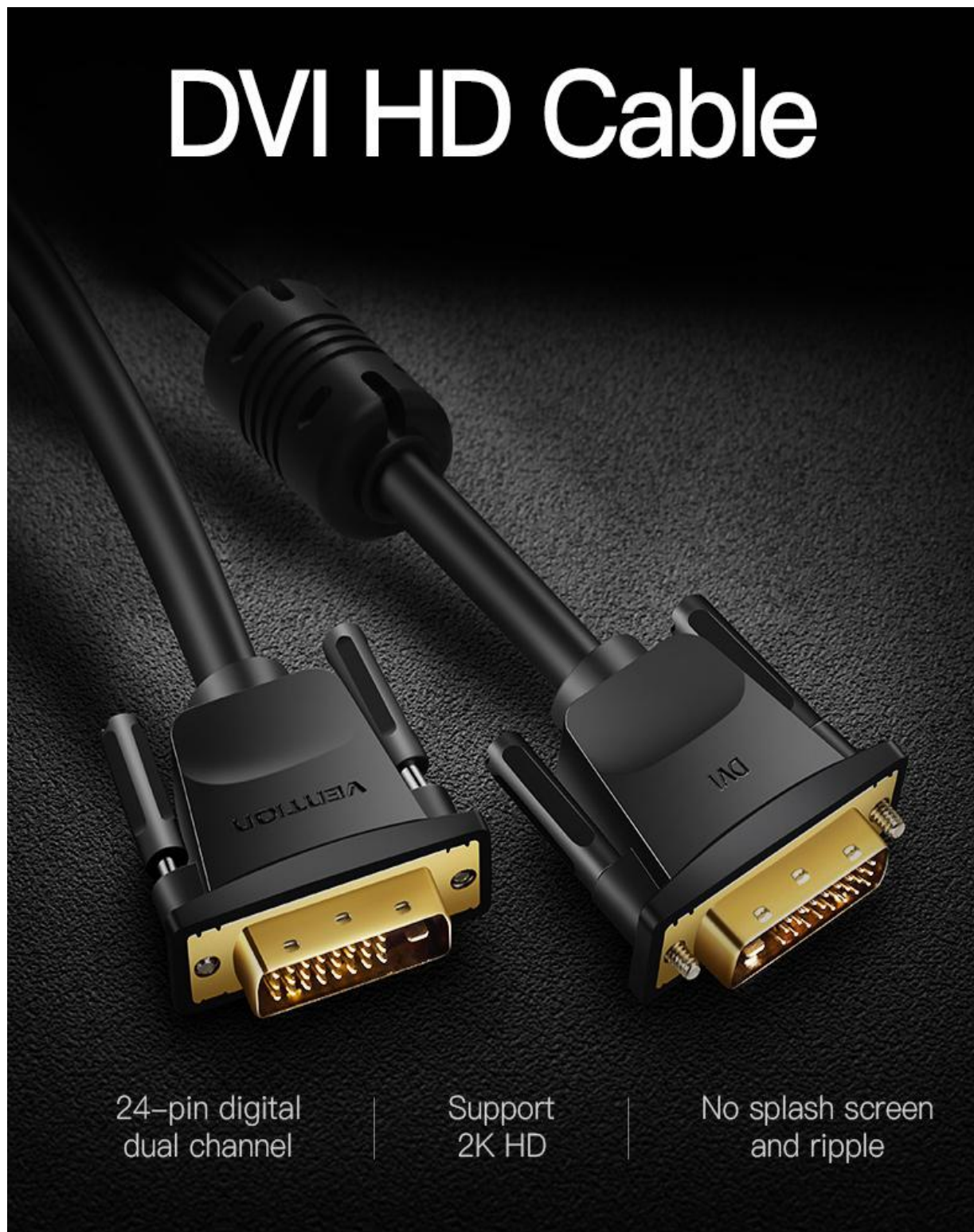

24-pin digital
dual channel

Support
2K HD


No splash screen
and ripple

24-Pin Digital Dual Channel Clearer Image

Supports 2560*1600 resolution
Faster refresh rate, more realistic



Reinforced SR Does Not Break

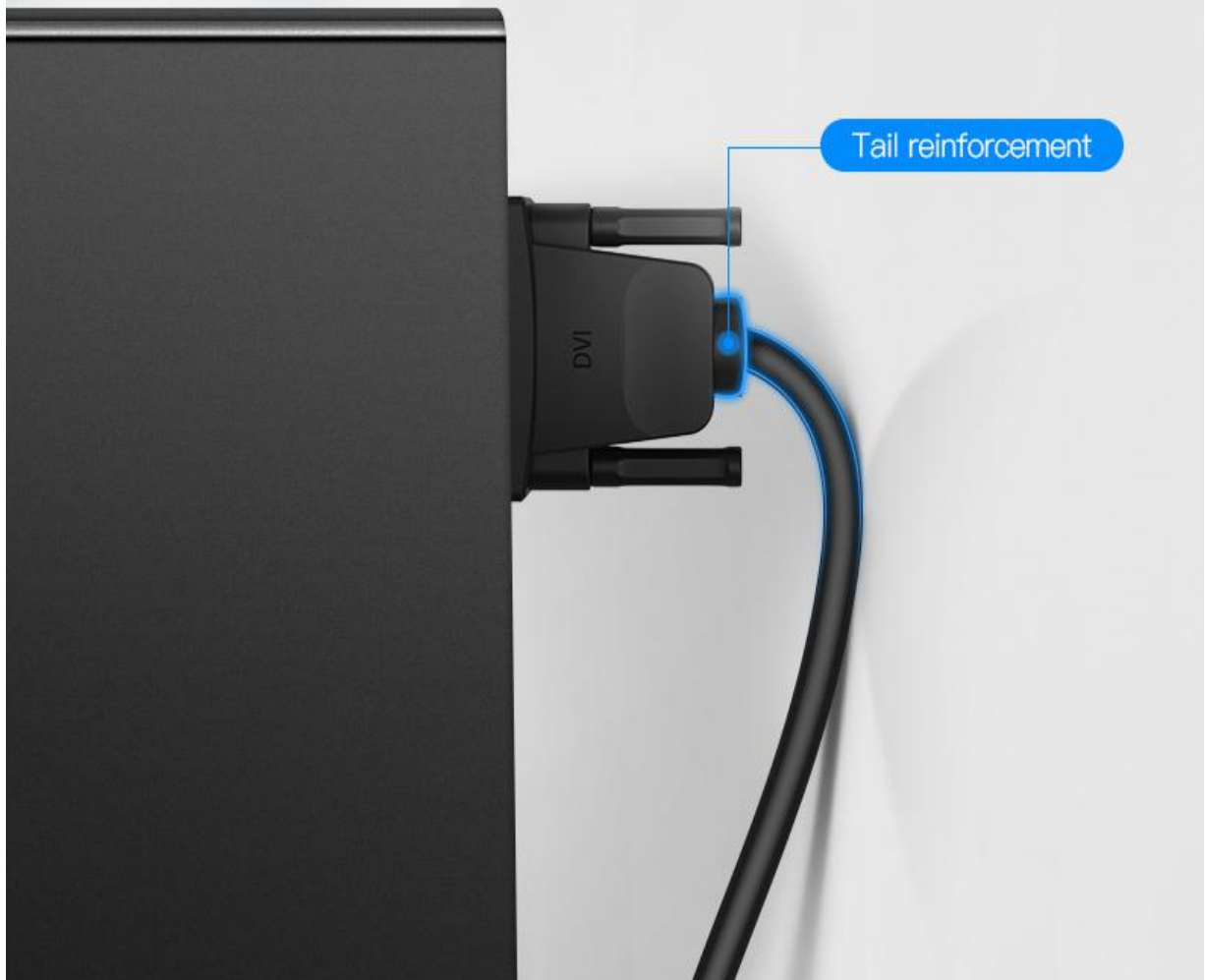

Magnetic Ring Anti-interference Anhydrous Ripple

Magnetic ring strengthen isolated electrical EMI/FRI signal interference,make video more clear




Magnetic ring instructions

	Length	Wire gauge	Wire diameter	Strengthen the configuration
PVC section	1-3m	31AWG	8.6mm	Single magnetic ring
	5m	31AWG	8.6mm	Double magnetic ring
	8-10m	28AWG+31AWG	8.6mm	Double magnetic ring
	15m	26AWG+30AWG	9mm	Double magnetic ring
	20-30m	30AWG+28AWG	10mm	Double magnetic ring and signal amplifier
Alloy models	1m-3m	30AWG+28AWG	8.0mm	—
	5m-8m	28AWG+28AWG	8.0mm	—
	10m	28AWG+26AWG	8.5mm	—

* These data are result from Vention laboratory

Great Material

Resist electromagnetic interference effectively
farewell splash, ghosting, ripple

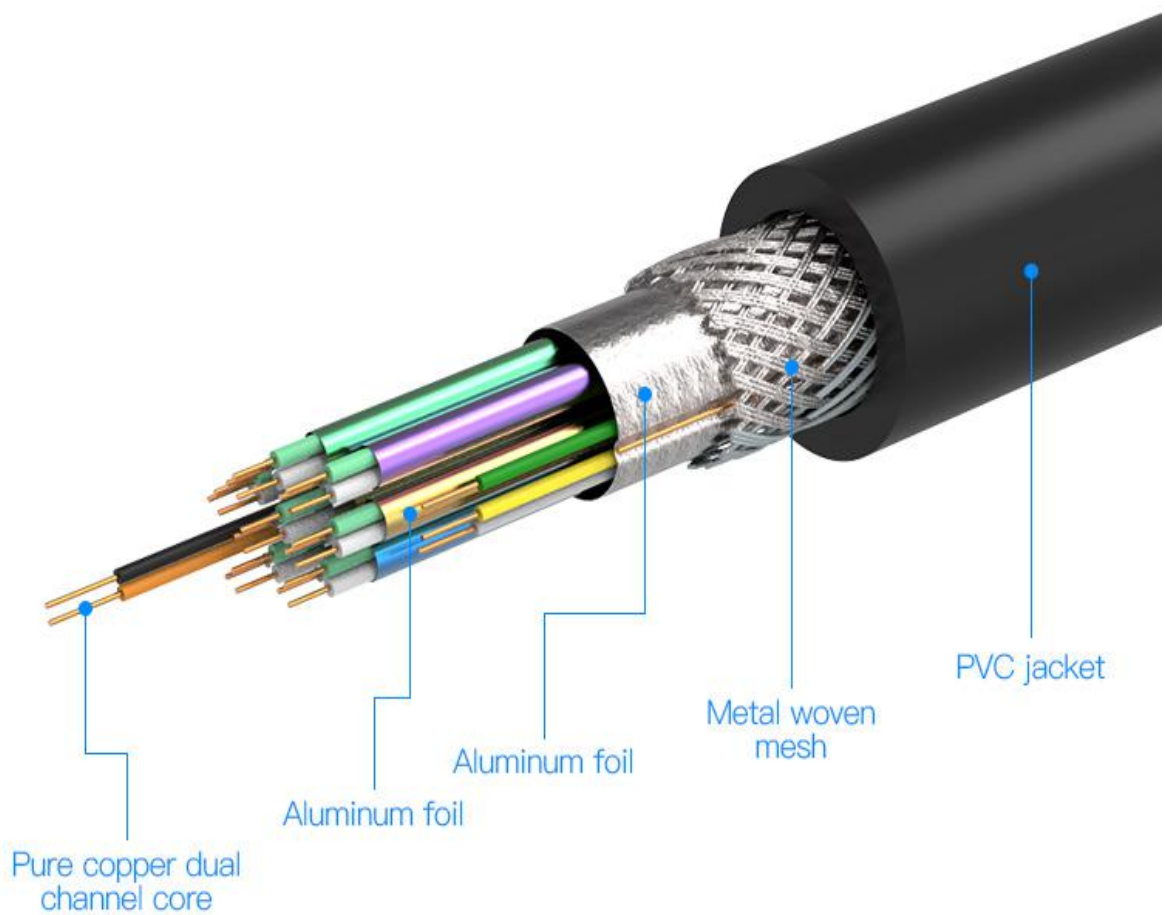

Signal Amplifier 30 Meters Still HD

20–30 meters equipped with signal amplifier
Prevents long-distance transmission signal attenuation
without dropping frames

INPUT

20 meters or more with directionality
INPUT terminated computer
OUTPUT Termination Monitor

* These data are result from Vention laboratory

OUTPUT

For A Variety of Devices

Connecting an output device with a DVI connector to a display device

Output
device



compute



Video card



Blu-ray
machine

display
screen



monitor



projector



TV




Enjoy 2K Digital HD

Big game is more realistic



Work More Efficiently

Notebook connect projector, enjoy large HD screen
work more efficiently

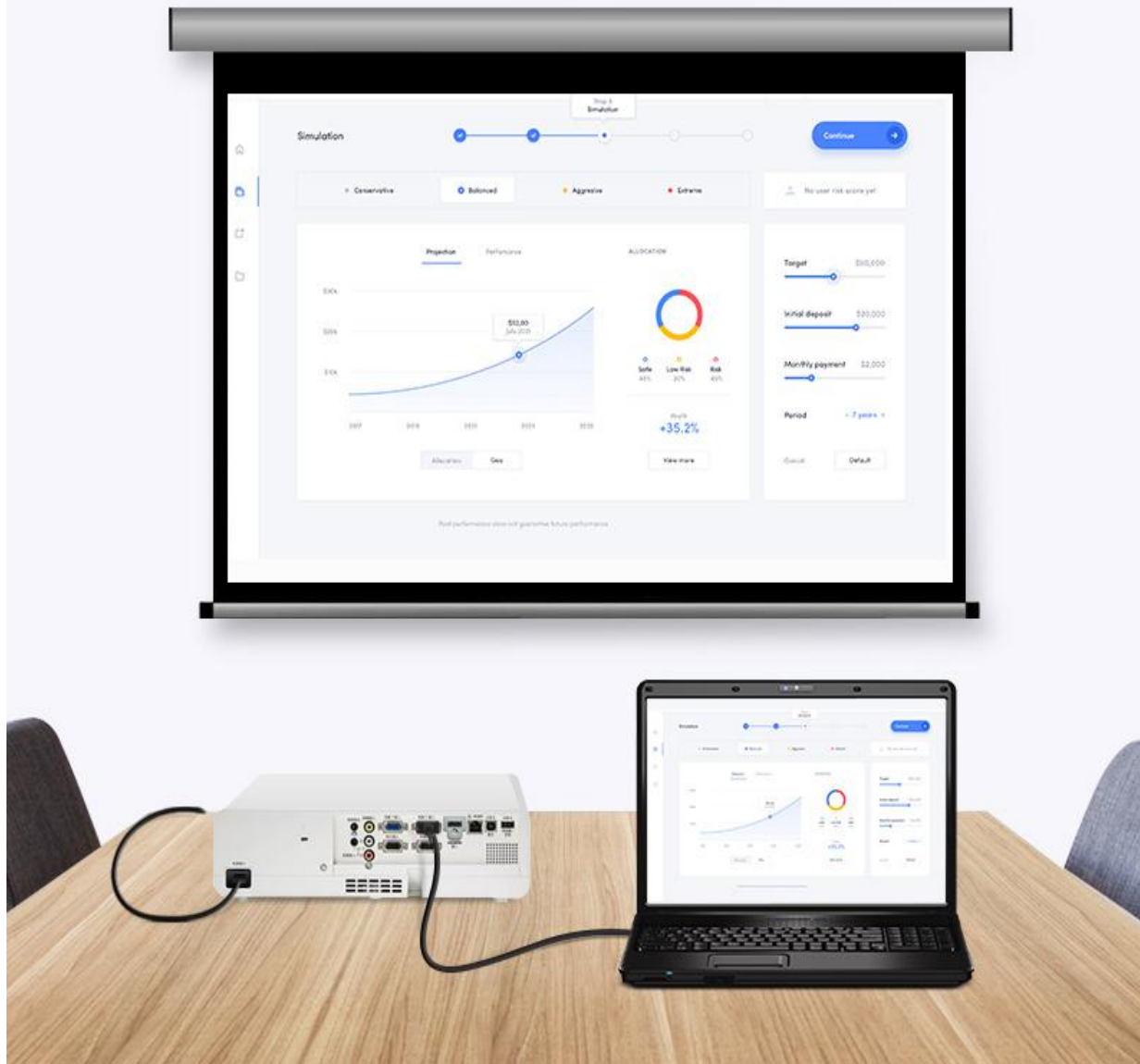

Product Parameters		
Color	Black	
Interface	DVI(24+1) Male	
Connector Process	Gold-plated	
Transmission Direction	DVI to DVI	
Resolution	2K@60Hz	
Conductor	Pure Copper	
Jacket	PVC	
Casing	PVC	
Cable OD	1-10m: 8.6mm15m: 9mm20-30m: 10mm	
Length	Art.No.	EAN Code
1m	EAABF	6922794731967
1.5m	EAABG	6922794731974
2m	EAABH	6922794731981
3m	EAABI	6922794731998
5m	EAABJ	6922794732001
8m	EAABK	6922794732018
		
Package Contents		
DVI Cable x 1		

Packaging Information	
Packing Dimension	mm
Packing Weight	kg
Carton Dimension	48*29*30mm (0.5m-5m)
Carton Qty	70pcs(1m)/60pcs(1.5m)/50pcs(2m)/40pcs(3m)30pcs(5m)28pcs(8m)
Carton Weight	1.62kg(1m)
Package	PE bag