


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936040069](#)
Status: **Active**
Overview: [GWconnect Heavy Duty Connectors \(HDC\)](#)
Description: GWconnect Enclosure, Die-cast Aluminum, S-8000 Series, with External Mounting Flanges, 166x 141 x 64mm Outside Dimensions, Grey RAL 7037

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Industrial Connectors / Enclosures
Series	93604
IP Rating	IP66
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Die-cast Enclosures
Product Name	GWconnect
Standard	ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 60670-1, EN 62208, EN-60670-22, NMX-J235/1-2
Type	ATEX
UPC	887191871448
Physical	
Enclosure Coating	Polyester Powder
Enclosure Color	Grey RAL 7037
Internal Dimensions	154 x 129 x 58mm
Material - Enclosure	Die-cast Aluminum
Mounting Style	External Flanges
Net Weight	590.150/g
Outside Dimensions	166 x 141 x 64mm
Packaging Type	Carton
Temperature Range - Operating	-20° to +85°C
Material Info	
Engineering Number	8000.6293.0

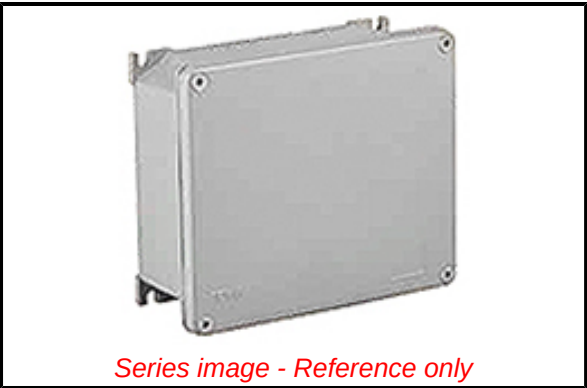

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - ECHA_01_2020 (16 January 2020 Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[93604](#) Series

Use With
DIN-rails, mounting supports, fixing screws,
metal plates, and ground terminals

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION