

Technical data sheet

Concealed connection box

Art.-Nr. 2003124



Connection box for clamping terminals, with cover and cover screw (15 mm), the cover edge is flat, surface is roughened, in conjunction with the cover and cover screws, the connection sockets achieve the VDE test mark to VDE 0606 and are flame-resistant to VDE 0471/DIN 695 Part 2-1, testing temperature 750 °C, protection rating IP20.

PS Polystyrene

Master data

Item no.	2003124
Type	UV 150 K
Description 1	Hollow wall, connection box
Description 2	concealed
Dimension	150x150x65
Colour	Black
Material	Polystyrene
Material symbol	PS
Smallest sales unit	16,00 Piece
Weight	15,67 kg/100 pc.


Technical data sheet

Concealed connection box

Art.-Nr. 2003124



Technical data

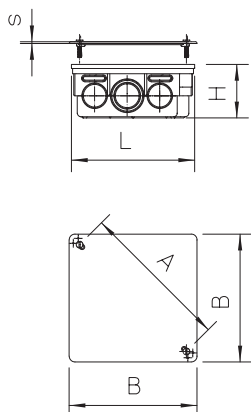

Width	150,00 mm
Height	65,00 mm
Length	150,00 mm
Dimension A	200,00 mm
Dimension B	170,00 mm
Dimension H	65,00 mm
Closable	☐
No. of entries	12,00
Entries	24
Type of entry	Break-out openings for cables and pipes 8 x Ø 21.5 mm and 12 x Ø 28.5 mm and 4 x Ø 34.6 mm
Type of housing penetration	Pre-marking
Version for	Single
Shape	Connection socket/box
Equipment	Without
Cover	Not transparent
Cover fastening	Screwed
Entry from rear	☐
Flame resistant	Flame resistant to VDE 0471/DIN 695 Part 2-1, test temperature 650 °C
Shape	Square
Function maintenance (ETIM)	Without
Floor height	67 mm
Halogen-free	☐
With screening	☐
With nail strap	☐
With bolts	☐
Mounting type	Concealed
Nominal cross section	16,00 mm ²
Nominal voltage	400,00 V
Sealable	☐
Impact-resistant	☒
Protection rating	IP20
Support	Without
Wind-tight	☐