


# Technical data sheet

## Box lid

Art.-Nr. 2003244

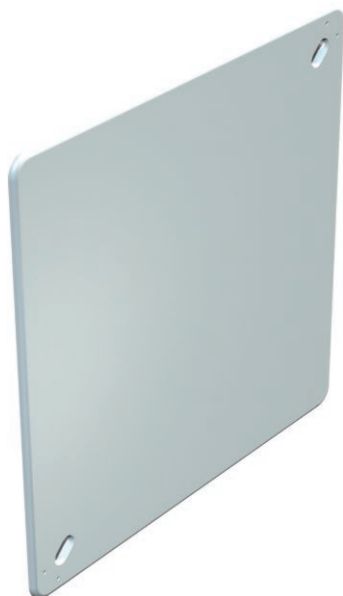

Box cover suitable for the connection sockets, type UV...K, cover edge is flush, surface is roughened, cover bolts can be lowered.



**PS** Polystyrene

### Master data

|                     |                 |
|---------------------|-----------------|
| Item no.            | 2003244         |
| Type                | UV 100 D        |
| Description 1       | Box lid         |
| Description 2       | concealed       |
| Dimension           | 114x114x1,5     |
| Colour              | White           |
| Material            | Polystyrene     |
| Material symbol     | PS              |
| Smallest sales unit | 10,00 Piece     |
| Weight              | 2,00 kg/100 pc. |


# Technical data sheet

## Box lid

Art.-Nr. 2003244



### Technical data

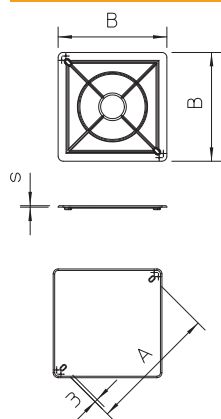

|                  |                                                                       |
|------------------|-----------------------------------------------------------------------|
| Width            | 114,00 mm                                                             |
| Height           | 1,50 mm                                                               |
| Length           | 114,00 mm                                                             |
| Dimension A      | 130,00 mm                                                             |
| Dimension B      | 114,00 mm                                                             |
| Dimension s      | 1,50 mm                                                               |
| Fastening type   | Screw-on lid                                                          |
| Cover            | Not transparent                                                       |
| Cover fastening  | Screwed                                                               |
| Flame resistant  | Flame resistant to VDE 0471/DIN 695 Part 2-1, test temperature 650 °C |
| Shape            | Square                                                                |
| Halogen-free     | <input checked="" type="checkbox"/>                                   |
| With bolts       | <input type="checkbox"/>                                              |
| Nominal voltage  | 400,00 V                                                              |
| Sealable         | <input checked="" type="checkbox"/>                                   |
| Impact-resistant | <input checked="" type="checkbox"/>                                   |