


Technical data sheet

Sprung cover, 80 mm

Art.-Nr. 2004634

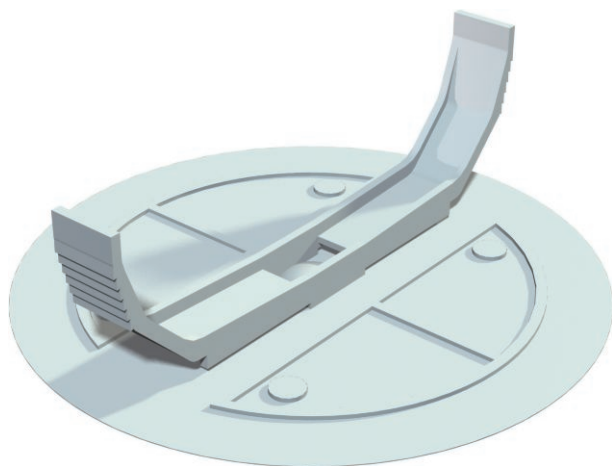

Sprung cover with centrally moulded, elastic spreading spring, for sockets with Ø 80 mm, cover edge is flush, surface is roughened.




PS Polystyrene

Master data

Item no.	2004634
Type	UV 80 FD
Description 1	Sprung lid
Description 2	Concealed
Dimension	Ø95mm
Colour	White
Material	Polystyrene
Material symbol	PS
Smallest sales unit	25,00 Piece
Weight	1,50 kg/100 pc.

Technical data

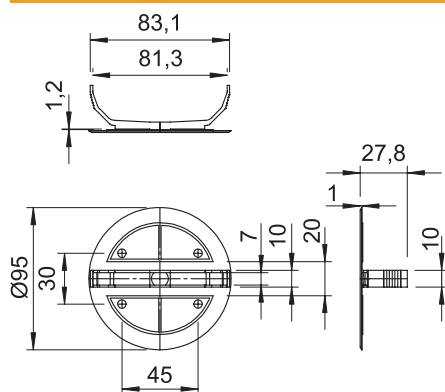

Height	1,00 mm
Ø	95 max.
Diameter	80,00 mm
Fastening type	Sprung cover
Flame resistant	Flame resistant to VDE 0471/DIN 695 Part 2-1, test temperature 750 °C
Shape	Round
Halogen-free	☒
With bolts	☐
Sealable	☐