

Product information

08 21 145

Needle-Nose Combination Pliers

DIN ISO 5746



- Small High Leverage Combination Pliers with pointed jaw.
- For all common installation and repair work.
- Handy use when working in confined areas thanks to slim head design and pointed jaws (anti-twist)
- Gripping surfaces with special convex contour on one side for secure gripping of flat parts
- Milled groove in the gripping area permits small parts such as nails, pins and bolts to be held and pulled
- The reliable and diverse combination pliers when out and about
- Easy cutting thanks to the high leverage joint
- With cutting edges for soft, medium-hard and hard wire
- Long service life and stable tips
- Forged from special high grade tool steel, manifold oil-hardened

General

Article No.	08 21 145
EAN	4003773078951
Pliers	black atramentized
Head	polished
Handles	plastic coated
weight	122 g
Dimensions	145 x 71 x 12 mm
Standard	DIN ISO 5746


Technische Attribute

Cutting capacities medium hard wire (diameter)	Ø 3.0 mm
Cutting capacities hard wire (diameter)	Ø 2.0 mm
Cutting capacity copper cable, multiple-stranded	Ø 8.0 mm
Cutting capacity copper cable, multiple-stranded	16.0 mm ²

Classification

eCl@ss 5.1.4	21040301
ETIM 6.0	EC000836
proficl@ss 6.0	AAA967c005
UNSPSC 13.1	27112139

technical change and errors excepted

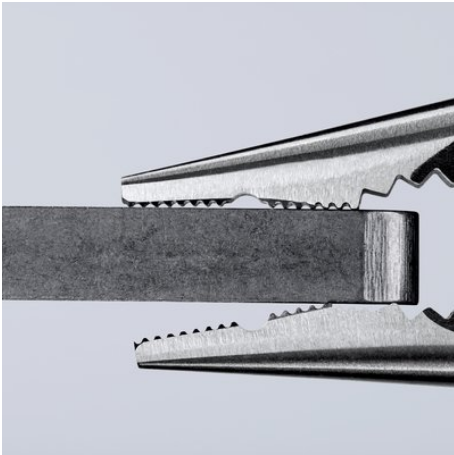

firm grip also on flat material due to three-point rest