

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0638130600

Status:


Active

Overview:

Application Tooling

Description:

Manual Activation and Deactivation Tool

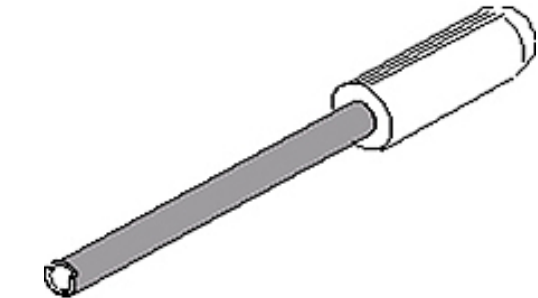

Series image - Reference only

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207122
Function	Activation, Deactivation
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	N/A
UPC	800753891920
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers

Application Tooling Documents

ATS-638130600, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207122 Series

Application Tooling Description	FAQ Product #
Sabre Crimp Terminal, Male, 18 AWG, 3.30mm Max. Insulation Diameter, Reel Packaged, Tin (Sn) Plated Brass Contact	431781002
Sabre Crimp Terminal, Male, 14-16 AWG or double 18-20 AWG, 4.57mm Max. Insulation Diameter, Reel Packaged, Tin (Sn) Plated Brass Contact	431782002
Sabre Crimp Terminal, Male, 18-20 AWG, 3.30mm max. Insulation Diameter, Reel	431784002

Packaged, Tin (Sn)
Plated Brass Contact
Sabre Crimp 431785002
Terminal, Male, 18
AWG, 3.30mm Max.
Insulation Diameter,
Reel Packaged,
Tin (Sn) Plated
Brass Contact, Last-
Make Wipe Length,
complies with the
UL1977 finger proof
access requirement
Sabre Crimp 431786002
Terminal, Male,
14-18 AWG, 4.57mm
Insulation Diameter,
Reel Packaged,
Tin (Sn) Plated
Brass Contact, Last-
Make Wipe Length,
complies with the
UL1977 finger proof
access requirement