

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0638247500

Status:

Active

Overview:

Application Tooling

Description:

Extraction Tool for CTX50 Contacts for Mini50 Sealed Connection System

Documents:

RoHS Certificate of Compliance (PDF)


General	
Product Family	Application Tooling
Series	207121
Comments	See Tooling Specification (PDF) Above
Function	Extraction
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	CTX50, Mini50 Sealed
Tool Type	Extraction Hand Tool
UPC	191128280273
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers

Application Tooling Documents

ATS-638247500-001

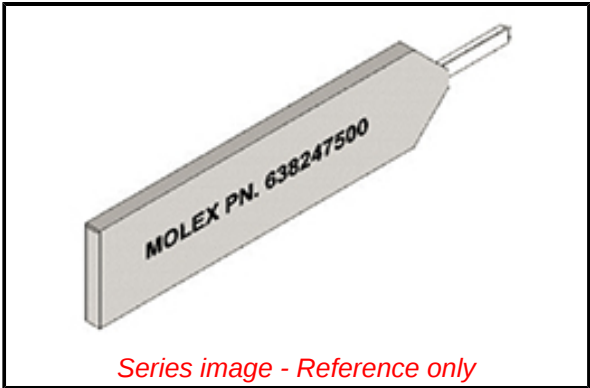

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207121 Series

Application Tooling Description	FAQ Product #
CTX50 Receptacle Terminal, Sealed, Tin, L-Grip, D-Wind, Left Payoff, Wire Insulation Diameter 1.20-1.40mm	349052447
CTX50 Receptacle Terminal, Sealed, Tin, S-Grip, D-Wind, Left Payoff, Wire Insulation Diameter 0.95-1.05mm	349052448
CTX50 Receptacle Terminal, Sealed, Tin, L-Grip, B-Wind, Right Payoff, Wire Insulation Diameter 1.20-1.40mm	349052449
CTX50 Receptacle Terminal, Sealed, Tin, S-Grip, B-Wind, Right Payoff, Wire	349052450

Insulation Diameter	
0.95-1.05mm	
CTX50 Receptacle	<u>349056447</u>
Terminal, Sealed,	
Silver, L-Grip,	
D-Wind, Left	
Payoff, Wire	
Insulation Diameter	
1.20-1.40mm	
CTX50 Receptacle	<u>349056448</u>
Terminal, Sealed,	
Silver, S-Grip,	
D-Wind, Left	
Payoff, Wire	
Insulation Diameter	
0.95-1.05mm	
CTX50 Receptacle	<u>349056449</u>
Terminal, Sealed,	
Silver, L-Grip,	
B-Wind, Right	
Payoff, Wire	
Insulation Diameter	
1.20-1.40mm	
CTX50 Receptacle	<u>349056450</u>
Terminal, Sealed,	
Silver, S-Grip,	
B-Wind, Right	
Payoff, Wire	
Insulation Diameter	
0.95-1.05mm	

This document was generated on 11/23/2020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION