


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0640011100](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: PremiumGrade Hand Crimp Tool for Avikrimp Female Fully Insulated Quick Disconnect Terminals, 14-16 AWG

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Application Tooling
Series	207129
Comments	Type RHT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	756054591864
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info	
Engineering Number	RHT-5762
Reference - Drawing Numbers	
Application Tooling Documents	ATS-640011100, TM-640160065, TM-640160065CN, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

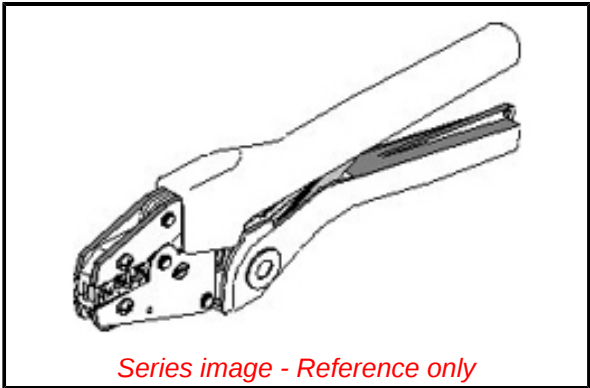

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Not Reviewed REACH SVHC Not Contained Per - ED/30/2017 (7 July 2017) Halogen-Free Status Not Relevant For more information, please visit Contact US	China RoHS
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[207129 Series](#)

Use With
Loose Piece Terminals

Application Tooling Description	FAQ Product #
Avikrimp Fully Insulated Quick Disconnect, Female, for 14-16 AWG Wire, Box	190020024
Avikrimp Fully Insulated Quick Disconnect, Female, for 14-16 AWG Wire, Box	190020028
Avikrimp Fully Insulated Quick Disconnect, Female, for 14-16 AWG Wire, Box	190020031
Avikrimp Fully Insulated Quick	190020034

Disconnect, Female,
for 14-16 AWG Wire,
Box
Avikrimp Fully 190020037
Insulated Quick
Disconnect, Female,
for 14-16 AWG Wire,
Box
Avikrimp Fully 190020040
Insulated Quick
Disconnect, Female,
for 14-16 AWG Wire,
Box
Avikrimp Fully 190020042
Insulated Quick
Disconnect, Female,
for 14-16 AWG Wire,
Box
Quixon Quick 192770005
Disconnect, Avikrimp
Style, Female, Fully
Insulated Blue, 14-16
AWG, Loose