

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0640010800

Status:

Active

Overview:

Application Tooling

Description:

PremiumGrade Hand Crimp Tool for Avikrimp Female Full Insulated Quick Disconnect Terminals, for 18-22 AWG with Insulation Diameter no greater than 3.175mm MAX

Documents:

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Comments

Function

Geographic Area

Level of Automation

More Detailed Tech Information

Overview

Product Name

Tool Type

UPC

Warranty Disclaimer

Application Tooling

207129

Type RHT

Crimp

Global

Manual

applicationtooling@molex.com

Application Tooling

N/A

Hand Crimp Tool

756054591895

CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info


Engineering Number

RHT-5760

Reference - Drawing Numbers

Application Tooling Documents

ATS-640010800-001, TM-640160065, TM-640160065CN, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

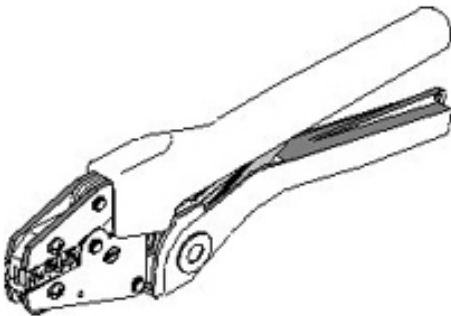

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China RoHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

207129 Series

Use With

Loose Piece Terminals

Application Tooling Description	FAQ Product #
Avikrimp Fully Insulated Quick Disconnect, Female for 18-22 AWG Wire, Box	190020001
Avikrimp Fully Insulated Quick Disconnect, Female, for 18-22 AWG Wire, Box	190020005
Avikrimp Fully Insulated Quick Disconnect, Female, for 18-22 AWG Wire, Box	190020009
Avikrimp Fully Insulated Quick	190020013

Disconnect, Female,
for 18-22 AWG Wire,
Box
Avikrimp Fully 190020016
Insulated Quick
Disconnect, Female,
for 18-22 AWG Wire,
Box
Avikrimp Fully 190020019
Insulated Quick
Disconnect, Female,
for 18-22 AWG Wire,
Box
Avikrimp Fully 190020021
Insulated Quick
Disconnect, Female,
for 18-22 AWG Wire,
Box
Quixon Quick 192770002
Disconnect, Avikrimp
Style, Female, Fully
Insulated Red, 18-22
AWG, Loose