

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0640031200

Status:

Active

Overview:

Application Tooling

Description:

Hand Crimp Tool

Documents:


RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207129
Comments	Type RHT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	822348563869
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Physical	
Net Weight	680.000/g

Material Info	
Engineering Number	RHT-1752

Reference - Drawing Numbers	
Application Tooling Documents	640031200, TM-640160065, TM-640160065CN, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

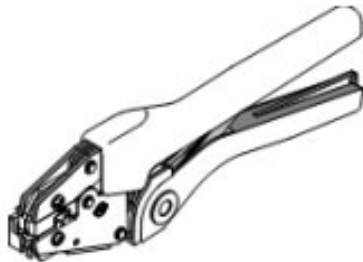

Series image - Reference only

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207129 Series

Use With

Loose Piece Terminals

Application Tooling Description	FAQ Product #
Krimptite Quick Disconnect, Female, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 2.79 x 0.51mm	190160035
Krimptite Quick Disconnect, Female, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 2.79 x 0.81mm	190160037
Krimptite Quick Disconnect, Female, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 4.75 x 0.51mm	190160039

Krimptite Quick Disconnect, Female, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 4.75 x 0.81mm	<u>190160040</u>
Krimptite Quick Disconnect, Female, for 12-14 (3.30-2.00mm ²) Wire, Box, Tab 4.75 x 0.51mm	<u>190160081</u>
Krimptite Quick Disconnect, Female, for 12-14 (3.30-2.00mm ²) Wire, Box, Tab 4.75 x 0.81mm	<u>190160082</u>
Krimptite Quick Disconnect, Female, for 12-14 (3.30-2.00mm ²) Wire, Box, Tab 6.35 x 0.81mm	<u>190160085</u>
Krimptite Quick Disconnect, Female, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 6.35 x 0.81mm	<u>190160111</u>
Krimptite Quick Disconnect, Male, for 18-22 (0.80-0.35mm ²) Wire, Box, Tab 6.35 x 0.81mm	<u>190220004</u>
Krimptite Quick Disconnect, Male, for 18-22 (0.80-0.35mm ²) Wire, Box, Tab 4.75 x 0.51mm	<u>190220006</u>
Krimptite Quick Disconnect, Male, for 14-16 AWG Wire, Box	<u>190220018</u>
Krimptite Quick Disconnect, Male, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 4.75 x 0.51mm	<u>190220022</u>
Krimptite Snap Plug Receptacle, for 14-16 AWG Wire, Box, 16.26mm Length	<u>190370004</u>
Krimptite Snap Plug Receptacle, for 14-16 AWG Wire, Box, 17.80mm Length	<u>190370006</u>
Krimptite Star Ring Tongue Terminal for	<u>190740001</u>

18-22 AWG Wire, Stud Size 6 (M3.5) Krimptite Star Ring	<u>190740004</u>
Tongue Terminal for 18-22 AWG Wire, Stud Size 8 (M4) Krimptite Star Ring	<u>190740007</u>
Tongue Terminal for 18-22 AWG Wire, Stud Size 10 (M5) Krimptite Steel	<u>190740009</u>
Star Ring Tongue Terminal for 18-22 AWG Wire, Stud Size 6 (M3.5) Krimptite Steel	<u>190740011</u>
Star Ring Tongue Terminal for 18-22 AWG Wire, Stud Size 8 (M4) Krimptite Steel	<u>190740013</u>
Star Ring Tongue Terminal for 18-22 AWG Wire, Stud Size 10 (M5) Krimptite Star Ring	<u>190740015</u>
Tongue Terminal for 14-16 AWG Wire, Stud Size 6 (M3.5) Krimptite Star Ring	<u>190740017</u>
Tongue Terminal for 14-16 AWG Wire, Stud Size 8 (M4) Krimptite Star Ring	<u>190740019</u>
Tongue Terminal for 14-16 AWG Wire, Stud Size 10 (M5) Krimptite Steel	<u>190740021</u>
Star Ring Tongue Terminal for 14-16 AWG Wire, Stud Size 6 (M3.5) Krimptite Steel	<u>190740023</u>
Star Ring Tongue Terminal for 14-16 AWG Wire, Stud Size 8 (M4) Krimptite Steel	<u>190740025</u>
Star Ring Tongue Terminal for 14-16 AWG Wire, Stud Size 10 (M5)	