
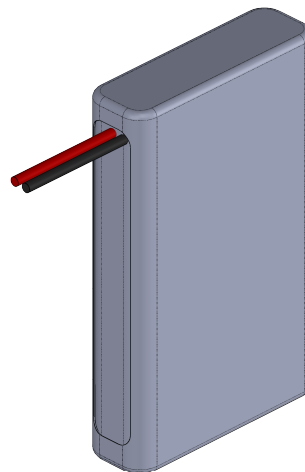
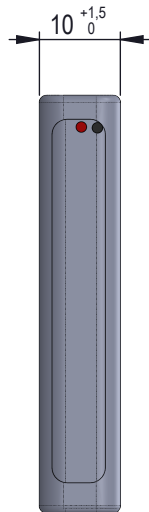


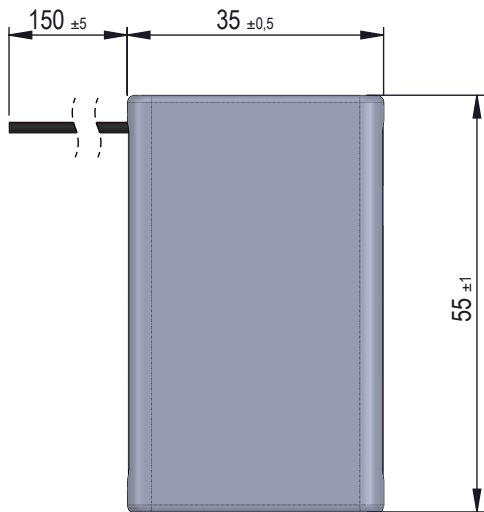


NCA 103450 / 1S1P

Specifications

Nominal Voltage [V]	3.6
Minimum Capacity [mAh]	2270
Rated Capacity [mAh]	2200
Charging Voltage [V]	4.2
Size [mm]	wg. rysunku
Weight [g]	50
Typical Charge [mA]	370
Rapid Charge [mA]	1295
max. Continuous discharge current [mA]	2000
Charge temperature	Typical 10°C -45°C Rapid 10°C-45°C
Discharge temperature	Continuous -20C- 60C
Storage temperature	Recommended -20C - 20C

LABEL: 45 x 25 mm

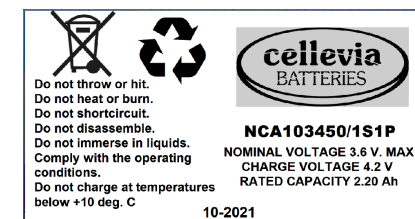

Material/ Material:	Scale/ Skala: 1:1	Sheet format/ Format arkusza: A4	Weight/ Masa: 50g	Sheet/ Arkusz: 1/3	Document revision/ Rewizja dokumentu: A
Finishing/ Wykończenie:	Date/ Data:				
Designed by/ Konstruował:	J.Dadacz				
Checked by/ Sprawdził:	S.Rybak				
Approved by/ Zatwierdził:	A.Smoliński				
Update/ Aktualizował:	Update/ Data aktualizacji:	Date of implementation/ Data wykonania:	Product reference/ Nazwa:		
J.Dadacz	2021-03-01	2012-10-19	Pakiet Li-ion NCA103450A 3,60V 2,35Ah 1S 1P Ver: 2 A		