




2411PD

Product no.: 2411PD

Needle nose pliers with very precise, smooth and rounded jaws, inside-serrated jaws for secure handling.

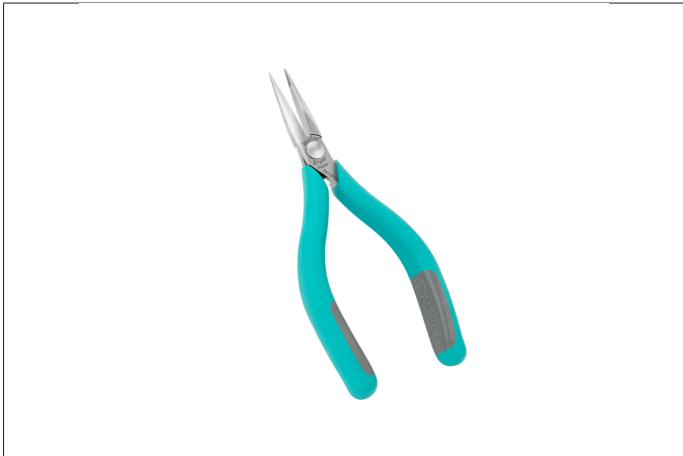

Pliers for miniature and standard electronics



Non-reflecting surface, ESD-safe



Optimized ergonomically shaped handles for increased comfort



[source images](#)

Built to Last - Longest lasting durability on the planet


The Weller Erem Series 2400 Magic Sense is a range of medium-sized precision cutters that combines robustness, visibility and accessibility. A large variety of head shapes for precision work in hard-to-reach areas. The optimized ergonomic shape of the Series 2400 MagicSense prevents hand fatigue. These cutters are manufactured from improved induction-hardened cutting edges up to 64 – 65 HRC for an extremely long service life. The cutting edges are made from special tool steel. The precision cutters have a nonreflecting surface, are ESD safe and resharpenable.

Type Type of Cut Cutting Capacity

Series 2400 MagicSense

mm 0,03 0,1 0,2 0,3 0,4 0,5 0,6 0,7 0,8 0,9 1,0 1,1 1,2 1,3 1,4 1,5 1,6 1,7 1,8 1,9 2,0
Inch .0001 .003 .007 .011 .015 .019 .023 .027 .031 .035 .039 .043 .047 .051 .055 .059 .062 .066 .070 .074 .078

Type	Type of Cut	Cutting Capacity
	Semi Flush	0,03 to 0,5 mm
	Flush	0,03 to 1,6 mm
	Super Full Flush	0,03 to 1,6 mm
	Flush	0,03 to 1,2 mm
	Flush	0,03 to 1,6 mm
	Flush	0,03 to 1,2 mm
	Flush	0,03 to 1,2 mm
	Flush	0,03 to 0,6 mm
	Flush	0,03 to 0,6 mm
	Flush / Carbide	0,03 to 1,2 mm

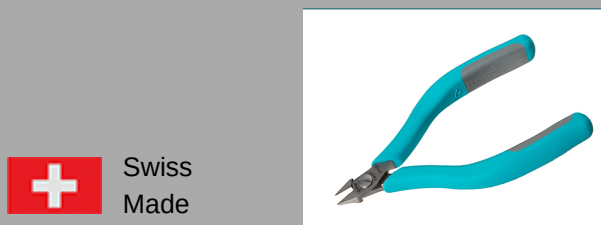



Technical Data

Length mm	150
Jaw length in mm	33.2
Head width mm	11
Head thickness mm	6
Width of tips in mm	1
Total height of both tips in mm	1.2
Length inches	5.291
Jaw length inches	1.307
Head width Inches	0.433
Head thickness Inches	0.236
Width of tips in Inches	0.039
Total height of both tips in Inches	0.047
ESD-safe	---
Erem applications	---
Material	Special tool steel
Weight in g	79.1
Weight in oz	2.790