




2482E

Product no.: 2482E

 
Tip cutter - angled narrow head.

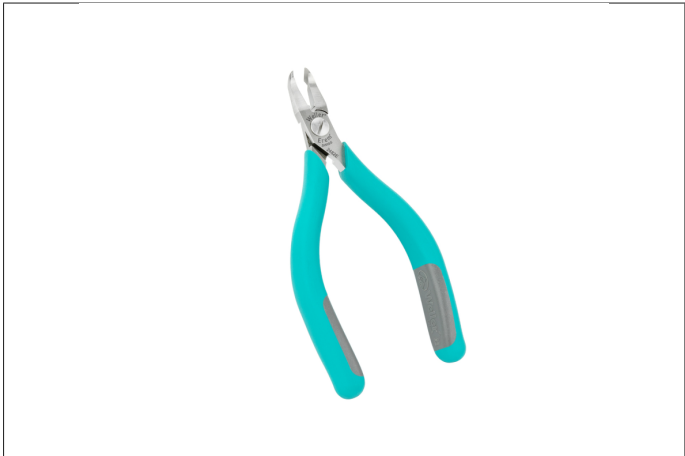

The angled head allows precise cuts at different working angles.



Suitable for working on printed-circuit boards, component connections, can be used in both 90° and 180° applications



source images

The Perfect Cut - Strong, sharp and precise, every time

The Weller Erem Series 2400 Magic Sense is a range of medium-sized precision cutters that combines robustness, visibility and accessibility. A large variety of head shapes for precision work in hard-to-reach areas. The optimized ergonomic shape of the Series 2400 MagicSense prevents hand fatigue. These cutters are manufactured from improved induction-hardened cutting edges up to 64 – 65 HRC for an extremely long service life. The cutting edges are made from special tool steel. The precision cutters have a nonreflecting surface, are ESD safe and resharpenable.

Type		Type of Cut	Cutting Capacity	
Series 2400 MagicSense			mm	0,03 0,1 0,2 0,3 0,4 0,5 0,6 0,7 0,8 0,9 1,0 1,1 1,2 1,3 1,4 1,5 1,6 1,7 1,8 1,9 2,0
			Inch	.0001 .003 .007 .011 .015 .019 .023 .027 .031 .035 .039 .043 .047 .051 .055 .059 .062 .066 .070 .074 .078
	2412E	Semi Flush		
	2422E	Flush		
	2432E	Super Full Flush		
	2477E	Flush		
	2403E	Flush		
	2404E	Flush		
	2482E	Flush		
	2475E	Flush		
	2470E	Flush		
	2476TX2	Flush / Carbide		





Technical Data

Length mm	135
Length of cutting edges mm	6
Head width mm	11
Head thickness mm	6
Head length mm	26
Max. cutting capability – hard wire mm	---
Weight in oz	2.677
Length of cutting edges Inches	0.236
Head width Inches	0.433
Head thickness Inches	0.236
Head length Inches	1.024
ESD-safe	on
Cut	Flush
Max. cutting capability – medium hardness mm	Ø 0,6
Max. cutting capability – copper wire mm	Ø 1,2
Length inches	5.315
Weight in g	75.9
Erem applications	Microelectronic