


Vario Clamping Block 25

094522M6CS

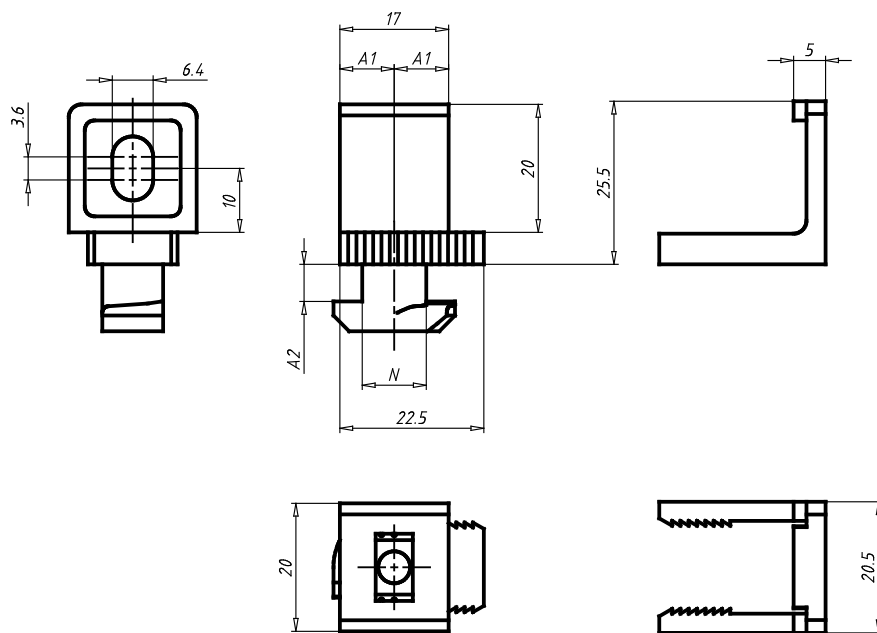

PARTNR (Part #)	N (/ mm)	T (Thread)	A1 (/ mm)	A2 (Profile / mm)	PROFILE (Profile)	WEIGHT (Weight / g)	CTN (Customs Tariff Number)	ID (ID #)
094522M6CS	10	M6	8.5	5.8 (6.0)	B	8.8	39269097	129317