


Inner Connector R

099I90R10M

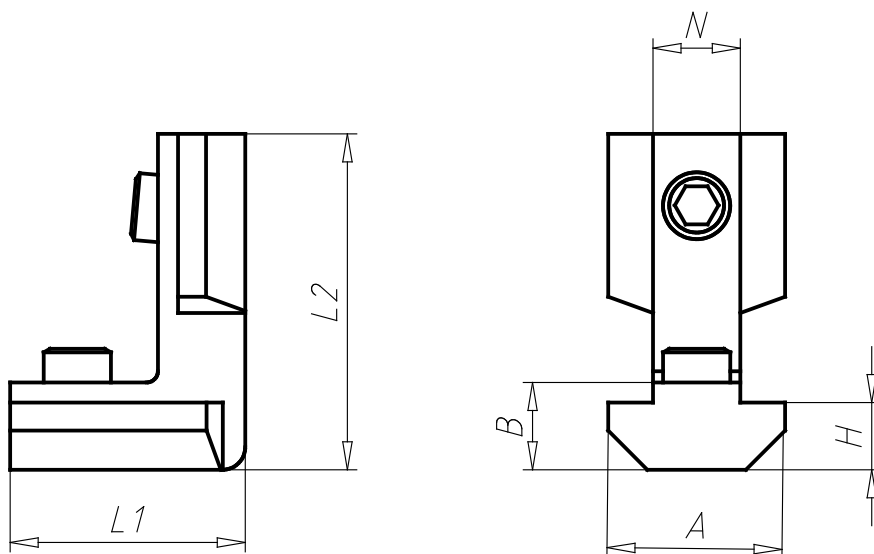

PARTNR (Part #)	PROFIL (Profile)	H (/ mm)	L1 (/ mm)	IC (Inner Connector R)	L2 (/ mm)	HS (Hexagon socket set screw)	N ()	A (/ mm)	B (/ mm)	WEIGHT (Weight / g)	CTN (Zolltarifnummer)	ID (ID-Nr.)
099I90R10M	B	3.8	32	ST cast steel	38	M8	10	19	8.8	51	73259990	132684