


DC / AC INVERTER IPS-1200S

12VDC / 230VAC 1200W PURE SINE WAVE



Input voltage:	11÷15VDC
Output voltage :	230VAC
Maximum Power:	1200VA
Continuous Power:	600VA
Output voltage type:	PURE SINE WAVE
Overload protection :	YES
Short-current protection:	YES
Thermal protection:	YES
Soft START:	YES
Input overvoltage protection :	15VDC
Battery discharge warning:	YES
Operating temperature range:	0 ~ +40 °C
Efficiency:	> 92 %
Cooling type:	Active
Connectors:	Screw Connector M6
Output socket type:	French x 1
Housing type:	Aluminium
IP protection:	IP21
Dimensions LxBxH [mm]:	260x157x77
Weight:	2.2
Product code:	5905279203815

Technical details

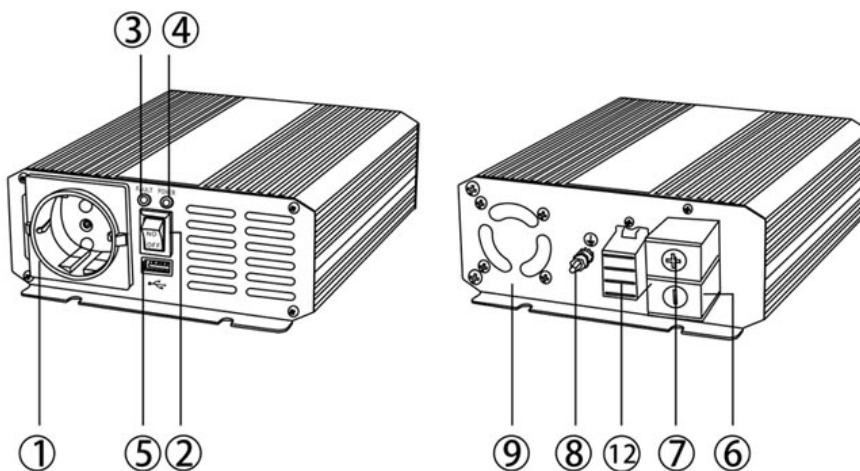

- 1 - 230V output socket
- 2 - Main switch
- 3 - LED indicator (Fault)
- 4 - LED indicator (Power)
- 5 - USB charging port

- 6 - Input voltage socket 12V (-)
- 7 - Input voltage socket 12V (+)
- 8 - Ground pin
- 9 - Fan
- 12 - Fuse

www.powerinverters.pl

Updated 17-02-2021



PROGRAM REGIONALNY
NARODOWA STRATEGIA SPÓJNOŚCI



Projekt współfinansowany przez Unię Europejską z Europejskiego Funduszu Rozwoju Regionalnego oraz z budżetu państwa.

