


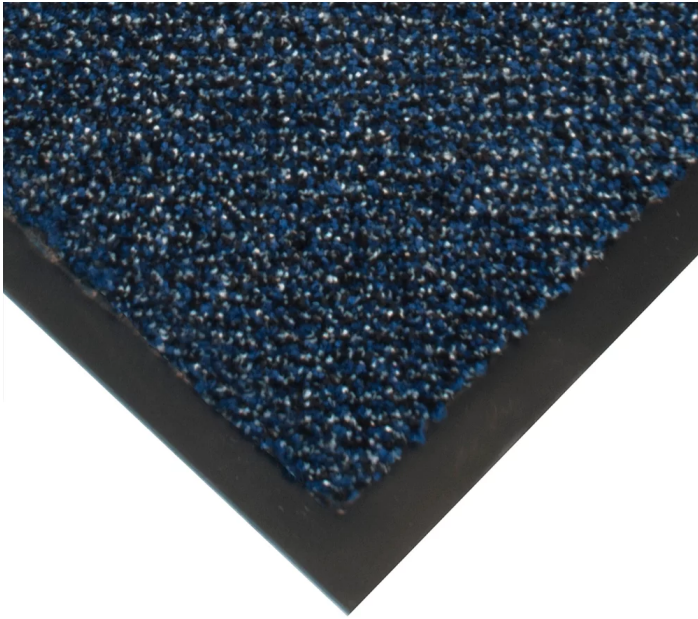


Cosmo Doormat

Superior fire tested doormat for busy entrances

1 | 2 | 3

- Hardwearing polyamide carpet surface doormat.
- Suitable durability for high traffic entrance areas.
- Fibres scrape and wipe moisture from footwear for effective floor protection.
- Fully fire tested – see datasheet for details.
- Anti-slip vinyl backing helps maintain mat position, even on smooth floors.
- UV and temperature resistant from 0°C to 60°C.

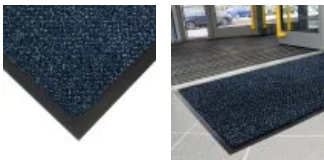

Styles Available




Beige



Brown



Blue

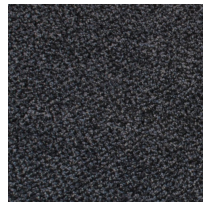

Grey

Parts

Part Number	Size	Colour	Weight
CSM010601	0.6 m x 0.9 m	Grey/Black	1.9 kg
CSM010602	0.9 m x 1.5 m	Grey/Black	4.7 kg
CSM010603	1.3 x 2 m	Grey/Black	9.1 kg
CSM060201	0.6 m x 0.9 m	Grey/Blue	1.9 kg
CSM060202	0.9 m x 1.5 m	Grey/Blue	4.7 kg
CSM060203	1.3 x 2 m	Grey/Blue	9.1 kg
CSM060501	0.6 m x 0.9 m	Grey/Brown	1.9 kg
CSM060502	0.9 m x 1.5 m	Grey/Brown	4.7 kg
CSM060503	1.3 x 2 m	Grey/Brown	9.1 kg

Technical Specification

Material	PA
Backing	Vinyl
Product Height	8 mm
Product Weight	3.5Kg/ m2
Operating Temperature	0°C to +60°C
Environmental Resistance	Suitable for indoor environments only
UV Resistance	Yes
Typical Applications	Entrance areas
Installation Method	Loose lay
Fire Tested to	Flame retardant to Cfl-S1.

CSM060701	0.6 m x 0.9 m	Grey/Beige	1.9 kg
CSM060702	0.9 m x 1.5 m	Grey/Beige	4.7 kg
CSM060703	1.3 x 2 m	Grey/Beige	9.1 kg

Country of Origin	Belgium
Coating Thickness	2 mm
Tuft density	110,000/ m2
Manufacturing process	Tufting 5/32'

Get in touch | To order FREE samples or arrange a site visit please call +44 (0)116 240 1088 or email sales@cobaeurope.com