




Vyna-Plush Doormat

The perfect low-cost doormat to scrape dirt and wipe moisture

- Budget doormat offering all-round performance to prevent slips and trips.
- 100% polypropylene fibres provide effective 'scraping' surface.
- Slip and stain-resistant PVC backing to keep your mat securely in place.
- Available in rolls for larger entrance areas.
- Range of bright colours available, to match interior theming.

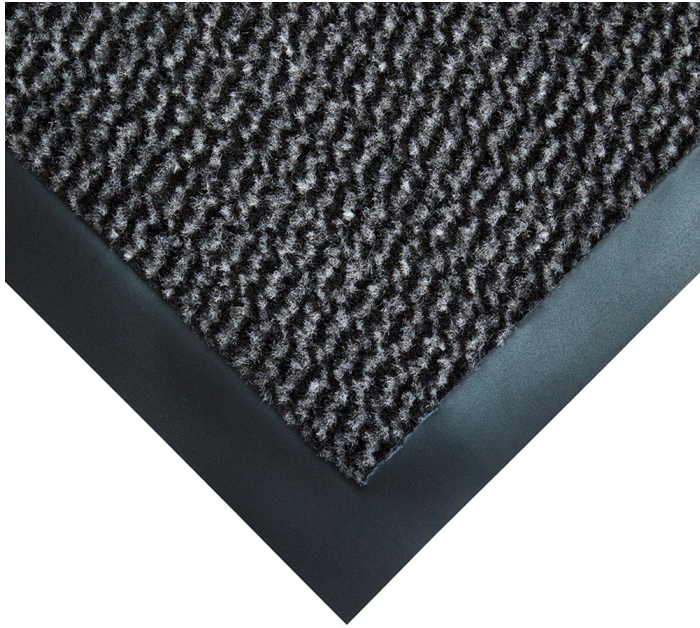

Styles Available

Black/Red

Black/Steel

Black/Brown

Black/Blue

Parts

Part Number	Size	Colour	Weight
VP010201	0.6 m x 0.9 m	Black/Blue	1.60 kg
VP010301	0.6 m x 0.9 m	Black/Red	1.60 kg
VP010501	0.6 m x 0.9 m	Black/Brown	1.60 kg
VP010601	0.6 m x 0.9 m	Black/Steel	1.60 kg
VP010204	0.9 m x 1.2 m	Black/Blue	2.85 kg
VP010304	0.9 m x 1.2 m	Black/Red	2.85 kg
VP010504	0.9 m x 1.2 m	Black/Brown	2.85 kg
VP010604	0.9 m x 1.2 m	Black/Steel	2.85 kg

Technical Specification

Material	PP
Backing	Vinyl
Surface Finish	Cutpile
Product Height	7 mm
Product Weight	2.9kg/ m2 (tolerance 100g/ m2)
Roll Length	25lm
Pile Height	5 mm
Absorbency	0.6l/ m2
Pile Yarn Composition	100% PP
Pile Weight	0.43kg/ m2
Operating Temperature	-10°C to +50°C
Resistance to Chemicals	Good
Environmental Resistance	Suitable for indoor environments only
Typical Applications	Entrance areas

			kg
VP010202	0.9 m x 1.5 m	Black/Blue	3.80 kg
VP010302	0.9 m x 1.5 m	Black/Red	3.80 kg
VP010502	0.9 m x 1.5 m	Black/Brown	3.80 kg
VP010602	0.9 m x 1.5 m	Black/Steel	3.80 kg
VP010203	1.2 m x 1.8 m	Black/Blue	6.05 kg
VP010303	1.2 m x 1.8 m	Black/Red	6.05 kg
VP010503	1.2 m x 1.8 m	Black/Brown	6.05 kg
VP010603	1.2 m x 1.8 m	Black/Steel	6.05 kg
VP010207C	0.9 m x per linear metre (max. 25 m)	Black/Blue	2.60 kg
VP010307C	0.9 m x per linear metre (max. 25 m)	Black/Red	2.60 kg
VP010507C	0.9 m x per linear metre (max. 25 m)	Black/Brown	2.60 kg
VP010607C	0.9 m x per linear metre (max. 25 m)	Black/Steel	2.60 kg
VP010208C	1.2 m x per linear metre (max. 25 m)	Black/Blue	3.43 kg
VP010308C	1.2 m x per linear metre (max. 25 m)	Black/Red	3.43 kg
VP010508C	1.2 m x per linear metre (max. 25 m)	Black/Brown	3.43 kg
VP010608C	1.2 m x per linear metre (max. 25 m)	Black/Steel	3.43 kg

Installation Method	Loose lay
Cleaning Method	Vacuum top surface
Country of Origin	Belgium
Coating Thickness	2 mm
Tuft density	63,000/ m2
Manufacturing process	Tufting 5/32'

Get in touch | To order FREE samples or arrange a site visit please call +44 (0)116 240 1088 or email sales@cobaeurope.com