




COBAdot Rubber Matting


An easy to install choice for floor refurbishment

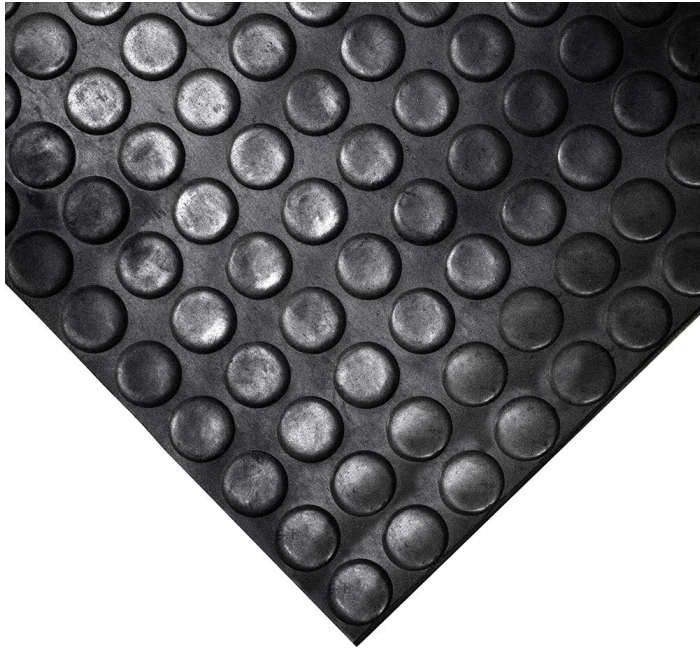

- Versatile rubber floor covering.
- Studded surface looks smart, while being a practical choice for both industrial and commercial buildings.
- Nitrile option recommended for oily, greasy or chemical-prone locations based on its resilient properties.
- Provides enhanced underfoot grip to reduce the risk of slipping.
- Ease of installation minimises any down time – can be bonded or laid loose to the floor.



Styles Available

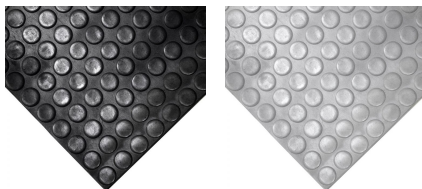

Black

Grey

Parts

Part Number	Size	Colour	Weight
CDS010001	1.2 m x 10 m x 3 mm	Black	45.45 kg
CDS010001C	1.2 m x per linear metre x 3 mm	Black	4.54 kg
CDS010002	1.2 m x 10 m x 4.5 mm	Black	80.35 kg
CDS010002C	1.2 m x per linear metre x 4.5 mm	Black	7.80 kg
CDS060001	1.2 m x 10 m x 3 mm	Grey	45.45 kg
CDS060001C	1.2 m x per linear metre x 3	Grey	4.54 kg

Technical Specification

Material	Standard - Natural/Synthetic rubber. Nitrile - Natural/NBR rubber.
Surface Finish	Studded
Product Height	3 mm or 4.5 mm
Roll Length	10 m
Operating Temperature	-30°C to +70°C
Resistance to Chemicals	Resistant to mild acids and alkalis
Environmental Resistance	Suitable for dry indoor environments
Typical	Walkways

	mm		
CDS060002	1.2 m x 10 m x 4.5 mm	Grey	80.35 kg
CDS060002C	1.2 m x per linear metre x 4.5 mm	Grey	7.80 kg
CDN010001	1.2 m x 10 m x 3 mm	Black Nitrile	51.00 kg
CDN010001C	1.2 m x per linear metre x 3 mm	Black Nitrile	4.50 kg
CDN010002	1.2 m x 10 m x 4.5 mm	Black Nitrile	73.85 kg
CDN010002C	1.2 m x per linear metre x 4.5 mm	Black Nitrile	7.38 kg
CDN060001	1.2 m x 10 m x 3 mm	Grey Nitrile	51.00 kg
CDN060001C	1.2 m x per linear metre x 3 mm	Grey Nitrile	4.50 kg
CDN060002	1.2 m x 10 m x 4.5 mm	Grey Nitrile	73.85 kg
CDN060002C	1.2 m x per linear metre x 4.5 mm	Grey Nitrile	7.38 kg

Applications	
Installation Method	Loose laid or bonded to the floor surface
Country of Origin	China or UAE